

Eaton XT IEC contactor

XTCR012B21D

UPC:782116884988

Dimensions:

- **Height:** 68 MM
- **Length:** 117 MM
- **Width:** 90 MM

Weight:..23 KG

Notes:Screw terminals (6-65A); 5 mm (80-150A);
no lugs (185-2000A)

Warranties:


- 1 year

Specifications:

- **Amperage Rating:** 12A
- **Coil Voltage:** 550 Vac 50 Hz, 600 Vac, 60 Hz
- **Contact Configuration:** 2NO-2NO
- **Frame Size:** 45 mm
- **Frequency Rating:** 50-60 Hz
- **Max Hp Rating:** 0.5, 2/ 3, 3, 10, 10 hp (1/3PH @115,230/200,230,460,575 V)
- **Number Of Poles:** Three-pole
- **Operation:** Reversing
- **Series:** XT IEC series
- **Terminals:** Screw terminals
- **Type:** Full voltage reversing contactor

Supporting documents:

- [Eaton's Volume 5-Motor Control and Protection](#)
- [XTCR_B 3D Inventor](#)
- [XTCR_B 2D Drawing Xchange](#)
- [XTCR_B AutoCAD 2D Footprint \(mm\)](#)
- [XTCR_B 3D Model Xchange](#)
- [XTCR_B AutoCAD 2D Footprint](#)
- [XTCR_B 2D PDF](#)
- [Eaton Specification Sheet - XTCR012B21D](#)

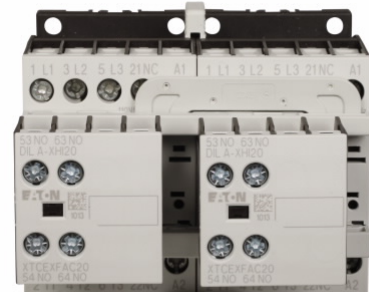

Certifications:

- EN 60947
- IEC 60947
- UL Listed
- CSA Certified

Product compliance:

- CE Marked
- RoHS Compliant

© 2016 Eaton. All rights reserved.