

## Eaton XT IEC contactor

XTCR012B21H

UPC:782116885022

### Dimensions:

- **Height:** 5 IN
- **Length:** 5.25 IN
- **Width:** 5.75 IN

**Weight:**1.5 LB

**Notes:**Screw terminals (6-65A); 5 mm (80-150A);  
no lugs (185-2000A)

### Warranties:


- 1 year

### Specifications:

- **Amperage Rating:** 12A
- **Coil:** 240V 50 hz, 277V 60 Hz
- **Coil Voltage:** 240 Vac 50 Hz, 277 Vac 60 Hz
- **Contact Configuration:** 2NO-2NO
- **Frame Size:** 45 mm
- **Frequency Rating:** 50-60 Hz
- **Max Hp Rating:** 0.5, 2/ 3, 3, 10, 10 hp (1/3PH @115,230/200,230,460,575 V)
- **Number Of Poles:** Three-pole
- **Operation:** Reversing
- **Series:** XT IEC series
- **Terminals:** Screw terminals
- **Type:** Full voltage reversing contactor

### Supporting documents:

- [Eaton's Volume 5-Motor Control and Protection](#)
- [XTCR\\_B 3D Model Xchange](#)
- [XTCR\\_B AutoCAD 2D Footprint \(mm\)](#)
- [XTCR\\_B 3D Inventor](#)
- [XTCR\\_B AutoCAD 2D Footprint](#)
- [XTCR\\_B 2D PDF](#)
- [XTCR\\_B 2D Drawing Xchange](#)
- [Eaton Specification Sheet - XTCR012B21H](#)

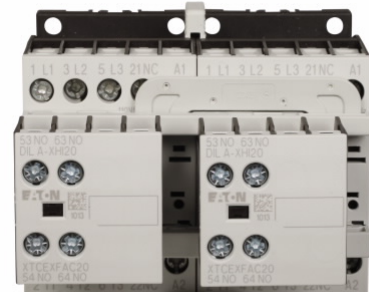

**Certifications:**

- EN 60947
- UL Listed
- CSA Certified
- IEC 60947

**Product compliance:**

- CE Marked
- RoHS Compliant

---

© 2016 Eaton. All rights reserved.