

## Eaton XT IEC contactor

**XTCR025C21H**

**UPC:**782116885428

### Dimensions:

- **Height:** 4.5 IN
- **Length:** 4.75 IN
- **Width:** 7.5 IN

**Weight:**2.45 LB

**Notes:**Screw terminals (6-65A); 5 mm (80-150A);  
no lugs (185-2000A)

### Warranties:


- 1 year

### Specifications:

- **Amperage Rating:** 25A
- **Coil:** 240V 50 hz, 277V 60 Hz
- **Coil Voltage:** 240 Vac 50 Hz, 277 Vac 60 Hz
- **Contact Configuration:** 2NO-2NO
- **Frame Size:** 45 mm
- **Frequency Rating:** 50-60 Hz
- **Max Hp Rating:** 2, 5/ 7.5, 10, 15, 20 hp (1/3PH  
@115,230/200,230,460,575 V)
- **Number Of Poles:** Three-pole
- **Operation:** Reversing
- **Series:** XT IEC series
- **Terminals:** Screw terminals
- **Type:** Full voltage reversing contactor

### Supporting documents:

- [Eaton's Volume 5-Motor Control and Protection](#)
- [XTCR\\_C 2D PDF](#)
- [XTCR\\_C 3D Model Xchange](#)
- [XTCR\\_C AutoCAD 2D Footprint](#)
- [XTCR\\_C 2D Drawing Xchange](#)
- [XTCR\\_C AutoCAD 2D Footprint \(mm\)](#)
- [XTCR\\_C 3D Inventor](#)
- [Eaton Specification Sheet - XTCR025C21H](#)

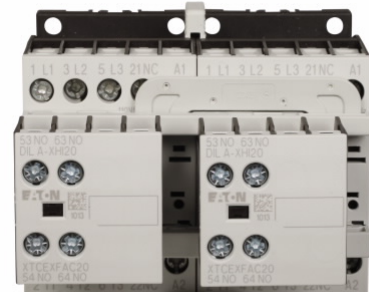

**Certifications:**

- CSA Certified
- IEC 60947
- EN 60947
- UL Listed

**Product compliance:**

- RoHS Compliant
- CE Marked

---

© 2016 Eaton. All rights reserved.