

Eaton XT IEC contactor

XTCR032C21D

UPC:782116885589

Dimensions:

- **Height:** 4.5 IN
- **Length:** 4.75 IN
- **Width:** 7.5 IN

Weight:2.45 LB

Notes:Screw terminals (6-65A); 5 mm (80-150A);
no lugs (185-2000A)

Warranties:


- 1 year

Specifications:

- **Amperage Rating:** 32A
- **Coil:** 550V 50 Hz, 600V 60 Hz
- **Coil Voltage:** 550 Vac 50 Hz, 600 Vac, 60 Hz
- **Contact Configuration:** 2NO-2NO
- **Frame Size:** 45 mm
- **Frequency Rating:** 50-60 Hz
- **Max Hp Rating:** 3, 5/ 10, 10, 20, 25 hp (1/3PH @115,230/200,230,460,575 V)
- **Number Of Poles:** Three-pole
- **Operation:** Reversing
- **Series:** XT IEC series
- **Terminals:** Screw terminals
- **Type:** Full voltage reversing contactor

Supporting documents:

- [Eaton's Volume 5-Motor Control and Protection](#)
- [XTCR_C 3D Model Xchange](#)
- [XTCR_C 3D Inventor](#)
- [XTCR_C AutoCAD 2D Footprint \(mm\)](#)
- [XTCR_C 2D PDF](#)
- [XTCR_C AutoCAD 2D Footprint](#)
- [XTCR_C 2D Drawing Xchange](#)
- [Eaton Specification Sheet - XTCR032C21D](#)

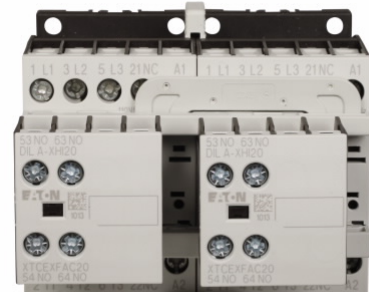

Certifications:

- UL Listed
- CSA Certified
- EN 60947
- IEC 60947

Product compliance:

- RoHS Compliant
- CE Marked

© 2016 Eaton. All rights reserved.