


**Starters — Non-reversing and Reversing**

*Not to be used for construction purposes unless approved.*

**Table 33-234. Open Reversing Starters Dimensions**

NEMA Size	Number of Poles	Fig.	Mounting Screws		Dimensions in Inches (mm)												Weight, Lbs. (kg)
			No.	Size	A	B	C	D	E	F	G	J	K	L	M	N	
00, 0, 1	3 x 3 Horiz.	A	3	#10	7.13 (181.1)	6.50 (165.1)	5.05 (128.3)	6.00 (152.4)	5.69 (144.5)	3.56 (90.4)	.25 (6.4)	2.3 (58.4)	.59 (15.0)	4.92 (125.0)	.27 (6.9)	—	9.0 (4.0)
	3 x 3 Vert.	B	3	#10	3.33 (84.6)	11.63 (295.4)	5.05 (128.3)	11.13 (282.7)	1.88 (47.8)	1.66 (42.2)	.25 (6.4)	.39 (9.9)	.59 (15.0)	4.92 (125.0)	.27 (6.9)	4.52 (114.8)	9.8 (4.4)
2	3 x 3 Horiz.	A	3	#10	7.13 (181.1)	7.25 (184.2)	5.38 (136.7)	6.75 (171.5)	5.69 (144.5)	3.56 (90.4)	.25 (6.4)	2.31 (58.7)	.77 (19.6)	4.97 (126.2)	.27 (6.9)	—	10.8 (4.9)
	3 x 3 Vert.	B	3	#10	3.33 (84.6)	12.38 (314.5)	5.38 (136.7)	11.88 (301.8)	1.88 (47.8)	1.66 (42.2)	.25 (6.4)	.39 (9.9)	.77 (19.6)	4.97 (126.2)	.27 (6.9)	4.52 (114.8)	12.2 (5.5)
3, 4	3 x 3 Horiz.	A	3	1/4 in.	9.75 (247.7)	10.13 (257.3)	7.25 (184.2)	9.25 (235.0)	8.00 (203.2)	4.88 (124.0)	.44 (11.2)	3.11 (79.0)	.80 (20.3)	6.86 (174.2)	.27 (6.9)	—	26.0 (11.8)
	3 x 3 Vert.	B	3	1/4 in.	4.63 (117.6)	19.81 (503.2)	7.25 (184.2)	18.94 (481.1)	2.88 (73.2)	2.94 (74.7)	.44 (11.2)	.55 (14.0)	.80 (20.3)	6.86 (174.2)	.27 (6.9)	7.91 (200.9)	28.0 (12.7)
5	3 x 3 Horiz.	—	4	3/8 in.	35.25 (895.4)	25.50 (647.7)	8.75 (222.3)	—	—	—	—	—	—	—	—	—	73.0 (33.1)
6	3 x 3 Horiz.	—	4	3/8 in.	35.25 (895.4)	25.50 (647.7)	10.50 (266.7)	—	—	—	—	—	—	—	—	—	127.0 (57.7)
7	①																
8	①																
9	①																

① Refer to factory.

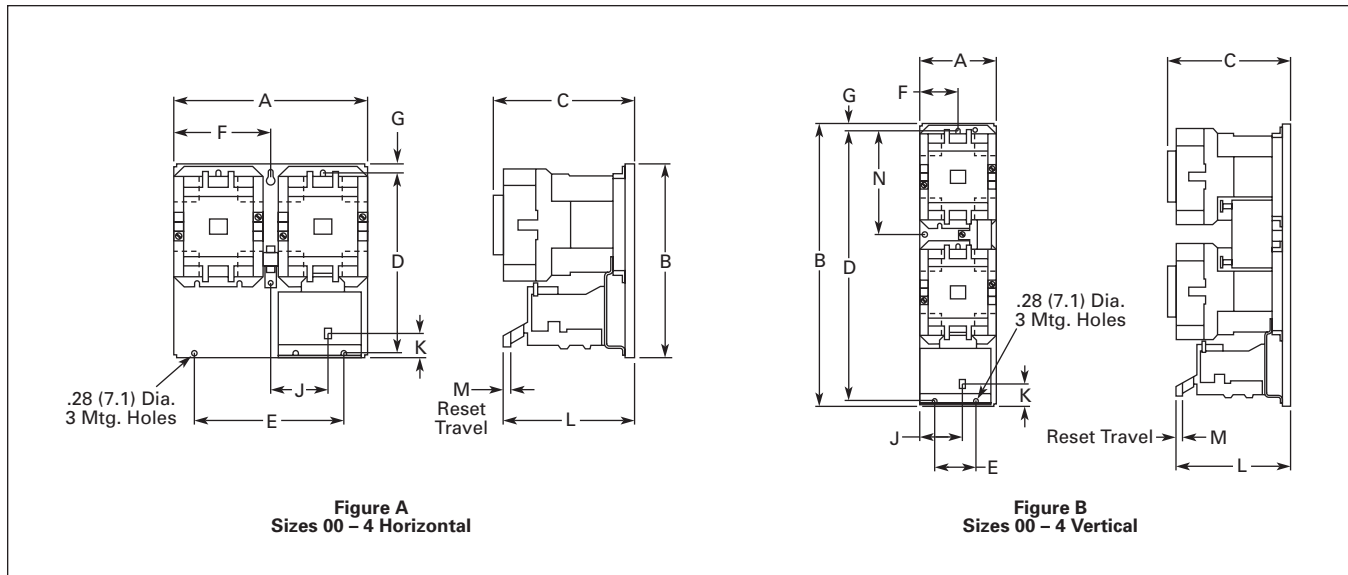

**Figure 33-65. Open Reversing Starters Dimensions**