






Transformer Specifications	
PRIMARY VOLTAGE(S)	230x460 (TRIPLE RATED)
SECONDARY VOLTAGE(S)	115
RATED V.A.	300
RATED FREQUENCY	50/60
INSULATION CLASS	130
AGENCY APPROVALS	UL, CUL
ESTIMATED WEIGHT	11.0 LBS

TEST REQUIREMENTS			
WINDING	H4-H3	H2-H1	X2-X1
D.C. VOLTS	240	240	127.5
LOAD VOLTS	240	240	120
F.L. AMPS	0.768	0.768	2.500
HI-POT	4800V		3000V
EXCITING AMPS	0.65AMPS @ 240 VOLTS, 50HZ		
EXCITING WATTS	24.5 MAX		

TERMINAL SCREWS ARE COMBINATION 8-32 PHIL-SLOT-1/4" HEX WITH SEMS WASHER

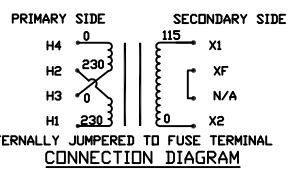

NOTE:
1. ALL MEASUREMENTS IN INCHES (MM)

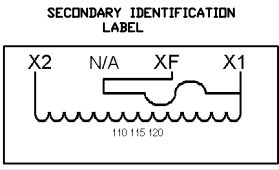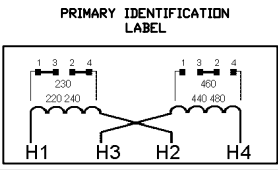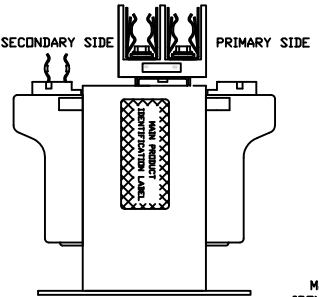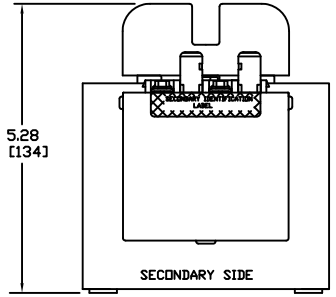

MAIN PRODUCT IDENTIFICATION LABEL

Cutler-Hammer INDUSTRIAL CONTROL TRANSFORMER
 300VA 50/60Hz
 TEMP CL. 130°C
 CAT. NO. C0300E2AFB
 SERIES 2
 B300-2166-8F
 Listed 702X 35082

PACKAGED ACCESSORIES	
1	1 PAIR OF JUMPERS
-	-
-	-
-	-

REV	DATE	BY	CHKD	DESCRIPTION
1	8/21/08	JLV	JKS	REVISED TO REFLECT CHANGES TO B300-2166-8F
2	8/21/08	JLV	JKS	REVISED TO REFLECT CHANGES TO B300-2166-8F
3	8/21/08	JLV	JKS	REVISED TO REFLECT CHANGES TO B300-2166-8F