


**SERIES CBT**

# CLIP-ON BIMETAL THERMOMETER

Fits Any Size Pot, Adjustable Set Point Pointer

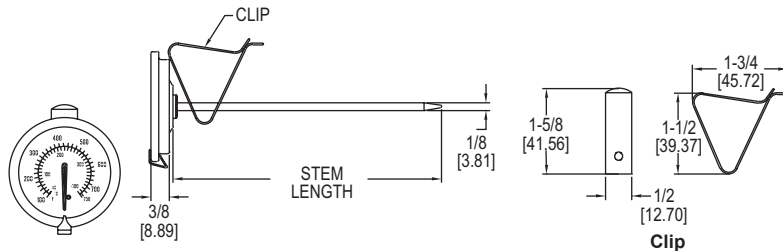

The **Series CBT Clip-On Thermometer** is designed to monitor the temperatures of products while they are cooking in pots, kettles, or other food preparation equipment.

**FEATURES/BENEFITS**

- Adjustable clip for easy mounting in pots or kettles
- Reference pointer

**APPLICATIONS**

- Food preparation monitoring
- Fryers or other kitchen equipment

SPECIFICATIONS	
<b>Wetted Materials:</b> 304 SS.	
<b>Housing Material:</b> Series 300 SS.	
<b>Lens:</b> Glass.	
<b>Accuracy:</b> ±1%.	
<b>Temperature Limits:</b> Ambient: 15 to 300°F (-10 to 150°C).	
<b>Dial Size:</b> 1-3/4", 2", and 3".	
<b>Resolution:</b> 2°.	
<b>Weight:</b> 2.3 oz (65 g).	

MODEL CHART											
Model	Dial Size	Stem Length	Range*	Model	Dial Size	Stem Length	Range*	Model	Dial Size	Stem Length	Range*
CBT175041	1-3/4"	5"	-40 to 160°F	CBT178071	1-3/4"	8"	50 to 500°F	CBT28051	2"	8"	0 to 250°F
CBT175051	1-3/4"	5"	0 to 250°F	CBT178052	1-3/4"	8"	-10 to 110°C	CBT28061	2"	8"	50 to 300°F
CBT175061	1-3/4"	5"	50 to 300°F	CBT25041	2"	5"	-40 to 160°F	CBT28071	2"	8"	50 to 500°F
CBT175071	1-3/4"	5"	50 to 500°F	CBT25051	2"	5"	0 to 250°F	CBT28052	2"	8"	-10 to 110°C
CBT175052	1-3/4"	5"	-10 to 110°C	CBT25061	2"	5"	50 to 300°F	CBT38041	3"	8"	-40 to 160°F
CBT178041	1-3/4"	8"	-40 to 160°F	CBT25071	2"	5"	50 to 500°F	CBT38051	3"	8"	0 to 250°F
CBT178051	1-3/4"	8"	0 to 250°F	CBT25052	2"	5"	-10 to 110°C	CBT38071	3"	8"	50 to 500°F
CBT178061	1-3/4"	8"	50 to 300°F	CBT28041	2"	8"	-40 to 160°F	CBT38052	3"	8"	-10 to 110°C

\*Dual scale units available by changing last digit to D. **Example:** CBT17504D