


Series
LTP

Single & Three Phase Solid State Relays

Zero-Crossover or Phase Angle Fired

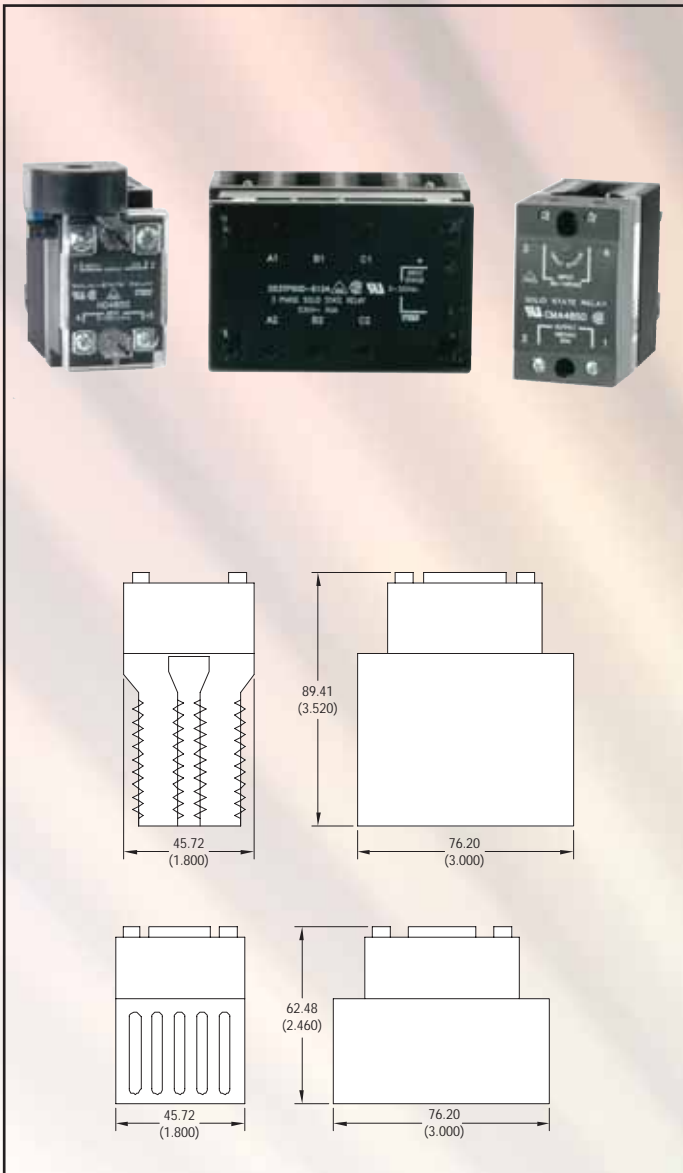

FEATURES

- Zero-Crossover or Phase Angle Fired
- Line (AC) or Low Voltage (DC) Triggers
- Single and Three Phase
- 240 VAC or 660 VAC Ratings
- Loads to 60 Amps
- High Efficiency Heat Sinks
- Easy DIN Rail Mounting

LTPZ125

Series 25 Amp Zero-Crossover Fired Single Phase SSR's

LTPZ125-240-D	240 VAC, 25 AMP Max. Load, 3-32 VDC Trigger
LTPZ125-240-A	240 VAC, 25 AMP Max. Load, 90-265 VAC Trigger
LTPZ125-660-D	660 VAC, 25 AMP Max. Load, 3-32 VDC Trigger
LTPZ125-660-A	660 VAC, 25 AMP Max. Load, 90-265 VAC Trigger

LTPZ140

Series 40 Amp Zero-Crossover Fired Single Phase SSR's

LTPZ140-240-D	240 VAC, 40 AMP Max. Load, 3-32 VDC Trigger
LTPZ140-240-A	240 VAC, 40 AMP Max. Load, 90-265 VAC Trigger
LTPZ140-660-D	660 VAC, 40 AMP Max. Load, 3-32 VDC Trigger
LTPZ140-660-A	660 VAC, 40 AMP Max. Load, 90-265 VAC Trigger

Love Controls LTP Series Solid State Relays allow easy control of most resistive and some inductive loads. Available in zero-crossover or phase angle fired versions, these compact solid state relays fit in many applications.

High Efficiency heat sinks allow for compact size. Combined with a convenient DIN Rail mount, these SSRs will fit where others won't. The LTT SSR Monitors and LTTJ Current Transformers mount conveniently on any of the single phase LTP Series SSRs.

Series
LTP


Single & Three Phase Solid State Relays

Zero-Crossover or Phase Angle Fired

Series LTPZ150

50 Amp Zero-Crossover Fired Single Phase SSR's


LTPZ150-240-D	240 VAC, 50 AMP Max. Load, 3-32 VDC Trigger
LTPZ150-240-A	240 VAC, 50 AMP Max. Load, 90-265 VAC Trigger
LTPZ150-660-D	660 VAC, 50 AMP Max. Load, 3-32 VDC Trigger
LTPZ150-660-A	660 VAC, 50 AMP Max. Load, 90-265 VAC Trigger

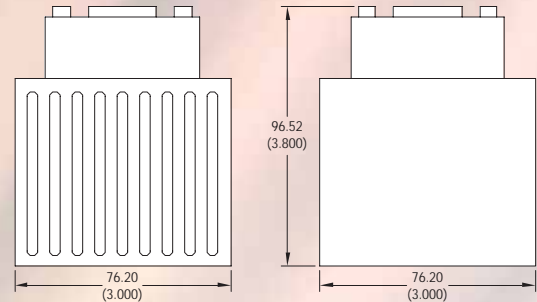

Series LTPZ160

60 Amp Zero-Crossover Fired Single Phase SSR's


LTPZ160-240-D	240 VAC, 60 AMP Max. Load, 3-32 VDC Trigger
LTPZ160-240-A	240 VAC, 60 AMP Max. Load, 90-265 VAC Trigger
LTPZ160-660-D	660 VAC, 60 AMP Max. Load, 3-32 VDC Trigger
LTPZ160-660-A	660 VAC, 60 AMP Max. Load, 90-265 VAC Trigger

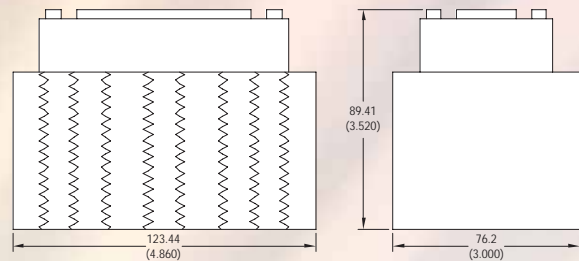


Series LTPZ330

30/40 Amp Zero-Crossover High Voltage Fired Three Phase SSR's

LTPZ330-530-D	530 VAC, 30 AMP Max. Load, 3-32 VDC Trigger
LTPZ330-530-A	530 VAC, 30 AMP Max. Load, 90-265 VAC Trigger
LTPZ340-530-D	530 VAC, 40 AMP Max. Load, 3-32 VDC Trigger
LTPZ340-530-A	530 VAC, 40 AMP Max. Load, 90-265 VAC Trigger

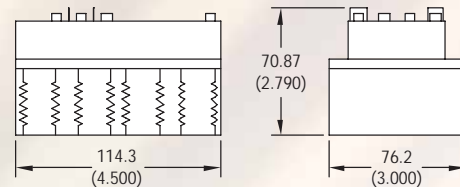

LTPZ330-

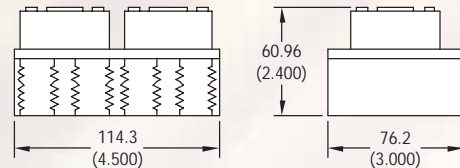

LTPZ340-

Series LTPP125

Phase Angle Fired Single Phase SSR's

LTPP125-240-4	240 VAC, 25 AMP Max. Load, 4-20 mA Trigger
LTPP125-660-4	660 VAC, 25 AMP Max. Load, 4-20 mA Trigger
LTPP125-240-P	240 VAC, 25 AMP Max. Load, 10 VDC or Pot. Trigger
LTPP140-660-P	660 VAC, 40 AMP Max. Load, 10 VDC or Pot. Trigger

