


# NAMUR MOUNT SOLENOID VALVE

## Manual Override, 100% Duty Rating

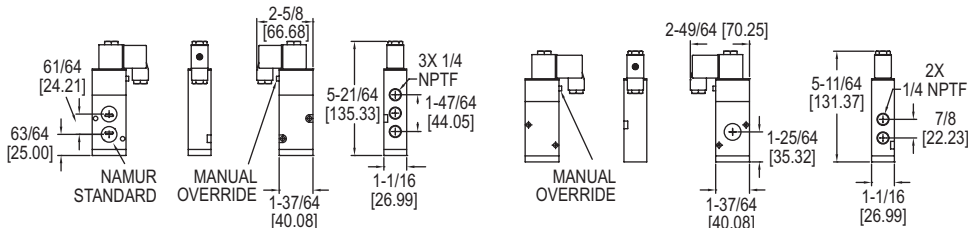

The **Series SN Namur Mount Solenoid Valve** is designed to easily mount directly to pneumatic valve actuators reducing the need for tubing, fittings or brackets, thereby reducing assembly cost. The SN solenoid comes with nitrile o-rings and offers a manual override as a standard feature. The 3/2 solenoids are designed for spring return actuators and 5/2 solenoids are designed to be used with double acting actuators. The SN series is available in a variety of voltages for any application.

### FEATURES/BENEFITS

- NAMUR mount means the solenoid can be mounted directly to valve actuators
- Designed for double acting or spring return actuators
- 100% continuous duty rating
- Manual override

### APPLICATIONS

- Direct mount to pneumatic actuators

MODEL CHART							
Model	Power	Action	Actuator Type	Model	Power	Action	Actuator Type
SN-5A	110 VAC	5/2	Double acting	SN-3A	110 VAC	3/2	Spring return
SN-5B	220 VAC	5/2	Double acting	SN-3B	220 VAC	3/2	Spring return
SN-5C	24 VAC	5/2	Double acting	SN-3C	24 VAC	3/2	Spring return
SN-5E	24 VDC	5/2	Double acting	SN-3E	24 VDC	3/2	Spring return
SN-5D	12 VDC	5/2	Double acting	SN-3D	12 VDC	3/2	Spring return

### SPECIFICATIONS

- Service:** Air only.
- Power Requirements:** 24 VAC, 110 VAC, 220 VAC, 12 VDC, or 24 VDC.
- Supply Pressure:** 22 to 116 psi (1.5 to 7.9 bar).
- Air Connections:** 1/4" female NPT.
- Temperature Limits:** 23 to 140°F (-5 to 60°C).
- Electrical Connection:** DIN 43650 form A.
- Enclosure Rating:** IP65.
- Mounting:** NAMUR.
- Standard Features:** Manual override.
- Weight:** 1.0 lb (.45 kg).
- Agency Approvals:** CE.



Model SN mounted to an actuator