

### Hospital grade straight blade plugs & connectors

#### Product description


2-pole, 3-wire grounding  
15A, 125V/AC  
NEMA 5-15




5-15P



5-15R

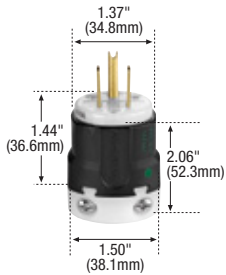

AH8215HG

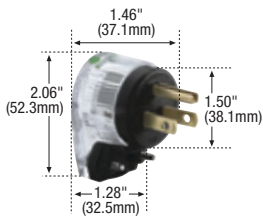

AH8215HGAC



AH8119W



5369NHG

#### Hospital grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
15	125	5-15	Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> AH8215HG	<input type="checkbox"/> AH8219HG	•	•
			Safety grip straight body	0.33-0.66" (8.3-16.7mm)	C	<input type="checkbox"/> AH8215HGC	<input type="checkbox"/> AH8219HGC	•	•
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> AH8215HGA	—	•	•
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	C	<input type="checkbox"/> AH8215HGAC	—	•	•
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	W	<input type="checkbox"/> AH8115W	<input type="checkbox"/> AH8119W	•	
			Auto grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> 5266NHG	<input type="checkbox"/> 5269NHG	•	•
			Auto grip isolated ground, straight body	0.33-0.66" (8.3-16.7mm)	RN	<input type="checkbox"/> IG5266NHG	—	•	•

### Hospital grade straight blade plugs & connectors

#### Product description

2-pole, 3-wire grounding  
20A, 125V/AC  
NEMA 5-20



5-20P



5-20R

#### Hospital grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	125	5-20	Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> AH8315HG <sup>†</sup>	<input type="checkbox"/> AH8319HG <sup>†</sup>	•	•
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> AH8315HGA <sup>†</sup>	—	•	•
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	C	<input type="checkbox"/> AH8315HGAC <sup>†</sup>	—	•	•
			Auto grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> 5366NHG	<input type="checkbox"/> 5369NHG	•	•

<sup>†</sup> Not NOM Spec

 
#### Hospital grade dimensional Information: B-16

#### Specification information:

Safety grip HG plugs & connectors: B-23  
Auto grip HG plugs & connectors: B-23  
Quick grip HG plugs & connectors: B-23

#### Color information:

BK (Black), C (Clear), RN (Orange), W (White)



Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32