

Industrial grade straight blade devices

Product description


2-pole, 3-wire grounding
20A, 125V/AC
NEMA 5-20



5-20P




5-20R

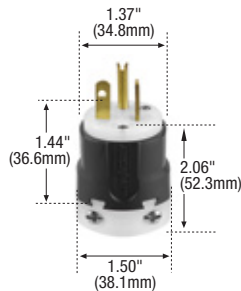

AH5366



AH5778C

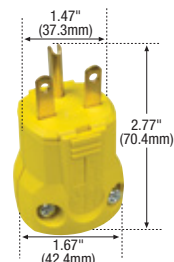

AH5666Y



AH5679C

Industrial grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	
20	125	5-20	Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	□ AH5366	□ AH5369	•
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	BK	□ AH5364BK	□ AH5369BK	•
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	Y	□ AH5364Y	□ AH5369Y	•

Industrial grade flanged inlets & outlets



Rating A	V/AC	NEMA	Description	Color	Inlet catalog no.	Outlet catalog no.	
20	125	5-20	Nylon construction, back wire	BK & W	□ AH5778C	□ AH5779C*	• •

* UL Listed only

Industrial grade straight blade devices

Product description

2-pole, 3-wire grounding
15A, 250V/AC
NEMA 6-15



6-15P



6-15R

Industrial grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	
15	250	6-15	Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	□ AH5666 [†]	□ AH5669 [†]	• •
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	BK, Y	□ AH5666__ [†]	□ AH5669__ [†]	•
			Auto grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	□ 5666N	□ 5669N	• •

[†] Not NOM Spec

Industrial grade flanged inlets & outlets



Rating A	V/AC	NEMA	Description	Color	Inlet catalog no.	Outlet catalog no.	
15	250	6-15	Nylon construction, back wire	BK & W	□ AH5678C	□ AH5679C*	• •

* UL Listed only

Industrial grade dimensional Information: B-16-B17

Specification Information:

Safety grip industrial plugs & connectors: B-24
Quick grip plugs & connectors: B-24
Auto grip industrial plugs & connectors: B-24
Industrial flanged inlets & flanged outlets: B-25

Color information:

BK (Black), W (White), Y (Yellow)



Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32