

1G

Gland type:

- Portable cord connector

Cable type:

- Non-armored

Features:


- Factory sealed conductors and seal on outer sheath of cable
- Three 12" long, #12 type SF-2 (150°C rating) stranded pigtails; two circuit wires and one identified grounding wire
- Three pressure connectors for 3-conductor cord, range #18 to #12 AWG
- Standard neoprene seal suitable for use in operating temperatures -25°C to 40°C
- Available with NPT threads

Certifications and compliances:

- UL, cUL Listed Class I, Division 1, Groups B, C, D
- Class II, Division 1, Groups, F, G – UL File No. E10279

Standard material:

- Body – aluminum

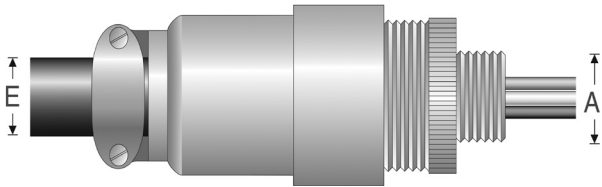

Ordering information:

Entry thread size (A)		Outer sheath (E)	
NPT size	Cat. #	Min.	Max.
3/4"	EBY2672	0.250	0.437
3/4"	EBY2682	0.375	0.500
3/4"	EBY26102	0.500	0.625

All dimensions in inches.