

Eaton 2607D63G01

Catalog Number: 2607D63G01

Disconnect switch, Visi-Flex DE-ION, 30A, #14-#4 Cu, Model A trip, Fusible, 3 hp at 120 Vac, 70-1/2 hp at 240 Vac, 20 hp at 480 Vac, 25 hp at 600 Vac, 5 hp at 250 Vdc, Not included

General specifications

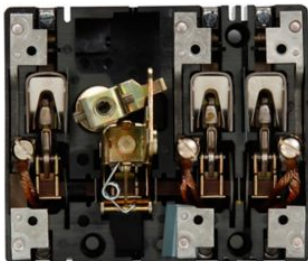


Photo is representative

Product Name

Eaton Type Visi-Flex DE-ION safety switch

Catalog Number

2607D63G01

UPC

786679612408

Product Length/Depth

7.5 in

Product Height

6.3 in

Product Width

6.2 in

Product Weight

3.75 lb

Warranty

Eaton Selling Policy 25-000, one (1) year UL Listed from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Certifications

Catalog Notes

External operating handle, shaft and fuse or no-fuse kit required

[Type](#)

Disconnect switch

[Amperage Rating](#)

30A

[HP rating - max](#)

3 hp at 120 Vac, 70-1/2 hp at 240 Vac, 20 hp at 480 Vac, 25 hp at 600 Vac, 5 hp at 250 Vdc

[Wire size](#)

#14-4 AWG Cu

[Fuse configuration](#)

Fusible

[Switch type](#)

Visi-Flex DE-ION

[Trip type](#)

Model A trip

[Catalogs](#)

[Eaton's Volume 2—Commercial Distribution](#)

[Multimedia](#)

[Single-phase disconnect and bypass switches](#)

[Specifications and datasheets](#)

[Eaton Specification Sheet - 2607D63G01](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)