

# Eaton 2607D63G06

Catalog Number: 2607D63G06

Disconnect switch, Visi-Flex DE-ION, 60A, #14-#4 Cu, Model A trip, Non-fusible, 7-1/2 hp at 120 Vac, 20 hp at 240 Vac, 40 hp at 480 Vac, 50 hp at 600 Vac, 10 hp at 250 Vdc

## General specifications

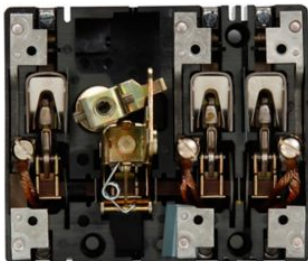


Photo is representative

<b>Product Name</b>	<b>Catalog Number</b>
Eaton Type Visi-Flex DE-ION safety switch	2607D63G06
	UPC
	786679612460

<b>Product Length/Depth</b>	<b>Product Height</b>
7.5 in	6.3 in

<b>Product Width</b>	<b>Product Weight</b>
6.2 in	3.85 lb

<b>Warranty</b>	<b>Certifications</b>
-----------------	-----------------------

Eaton Selling Policy 25-000, one (1) year UL Listed from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

### Catalog Notes

External operating handle, shaft and no-fuse kit required. Rated 600 volts. Special 60Aere switch has same dimension as 30Aere Visi-Flex switch.

[Type](#)

Disconnect switch

[Amperage Rating](#)

60A

[HP rating - max](#)

7-1/2 hp at 120 Vac, 20 hp at 240 Vac, 40 hp at 480 Vac, 50 hp at 600 Vac, 10 hp at 250 Vdc

[Wire size](#)

#14-4 AWG Cu

[Fuse configuration](#)

Non-fusible

[Switch type](#)

Visi-Flex DE-ION

[Trip type](#)

Model A trip

[Catalogs](#)

[Eaton's Volume 2—Commercial Distribution](#)

[Multimedia](#)

[Single-phase disconnect and bypass switches](#)

[Specifications and datasheets](#)

[Eaton Specification Sheet - 2607D63G06](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)