

Eaton 2607D89G11

Catalog Number: 2607D89G11

Disconnect switch, Visi-Flex DE-ION, 60A, #14-#4 Cu, Model A trip, Fusible, 5 hp at 480 Vac, 7-1/2 hp at 600 Vac, 5 hp at 250 Vdc, 30A at 600 Vac

General specifications

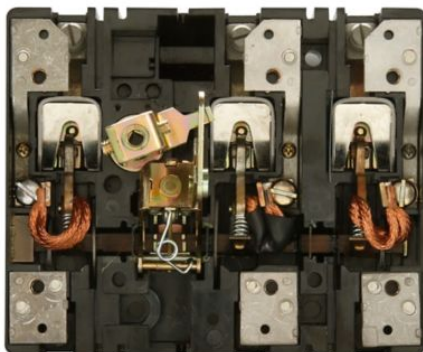


Photo is representative

Product Name	Catalog Number
Eaton Type Visi-Flex DE-ION safety switch	2607D89G11
	UPC
	786679990216

Product Length/Depth	Product Height
1 in	1 in

Product Width	Product Weight
1 in	0.1 lb

Warranty	Certifications
-----------------	-----------------------

Eaton Selling Policy 25-000, one (1) year UL Listed from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Catalog Notes

Shipped as basic switch, operating handle, shaft and fuse kit. Special 60Aere switch has same dimension as 30Aere Visi-Flex switch.

Type

Disconnect switch

Amperage Rating

60A

HP rating - max

5 hp at 480 Vac, 7-1/2 hp at 600 Vac, 5 hp at 250 Vdc

Wire size

#14-4 AWG Cu

Fuse clip rating

30 A at 600 Vac

Fuse configuration

Fusible

Switch type

Visi-Flex DE-ION

Trip type

Model A trip

Catalogs

[Eaton's Volume 2—Commercial Distribution](#)

Multimedia

[Single-phase disconnect and bypass switches](#)

Specifications and datasheets

[Eaton Specification Sheet - 2607D89G11](#)

Warranty guides

[Selling Policy 25-000 - Distribution and Control Products and Services](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)