

# Eaton 2607D89G12

Catalog Number: 2607D89G12

Disconnect switch, Visi-Flex DE-ION, 60A, #14-#4 Cu, Model A trip, Fusible, 15 hp at 480 Vac, 15 hp at 600 Vac, 10 hp at 250 Vdc, 60A at 600 Vac

## General specifications

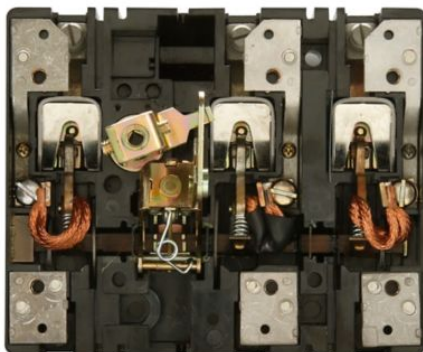


Photo is representative

<b>Product Name</b>	<b>Catalog Number</b>
Eaton Type Visi-Flex DE-ION safety switch	2607D89G12
	<b>UPC</b>
	786679990223

<b>Product Length/Depth</b>	<b>Product Height</b>
1 in	1 in

<b>Product Width</b>	<b>Product Weight</b>
1 in	0.1 lb

<b>Warranty</b>	<b>Certifications</b>
-----------------	-----------------------

Eaton Selling Policy 25-000, one (1) year UL Listed from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

### Catalog Notes

Shipped as basic switch, operating handle, shaft and fuse kit. Special 60Aere switch has same dimension as 30Aere Visi-Flex switch.

**Type**

Disconnect switch

**Amperage Rating**

60A

**HP rating - max**

15 hp at 480 Vac, 15 hp at 600 Vac, 10 hp at 250 Vdc

**Wire size**

#14-4 AWG Cu

**Fuse clip rating**

60 A at 600 Vac

**Fuse configuration**

Fusible

**Switch type**

Visi-Flex DE-ION

**Trip type**

Model A trip

**Catalogs**

[Eaton's Volume 2—Commercial Distribution](#)

**Multimedia**

[Single-phase disconnect and bypass switches](#)

**Specifications and datasheets**

[Eaton Specification Sheet - 2607D89G12](#)

**Warranty guides**

[Selling Policy 25-000 - Distribution and Control Products and Services](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)