

Eaton 2607D91G12

Catalog Number: 2607D91G12

Disconnect switch, Visi-Flex DE-ION, 100A, #14-1/0 Cu, Model A trip, Fusible, 25 hp at 480 Vac, 30 hp at 480 Vac, 100A at 600 Vac

General specifications

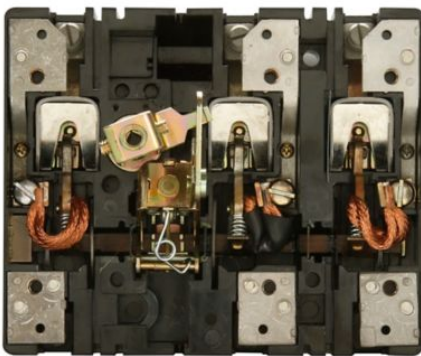


Photo is representative

Product Name
Eaton Type Visi-Flex DE-ION safety switch

Catalog Number
2607D91G12

UPC
786679990520

Product Length/Depth
1 in

Product Height
1 in

Product Width
1 in

Product Weight
0.1 lb

Warranty

Eaton Selling Policy 25-000, one (1) year UL Listed from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Certifications

Catalog Notes

Shipped as basic switch, operating handle, shaft and fuse kit

Type

Disconnect switch

Amperage Rating

100A

HP rating - max

25 hp at 480 Vac, 30 hp at 480 Vac

Wire size

#14-1/0 AWG Cu

Fuse clip rating

100 A at 600 Vac

Fuse configuration

Fusible

Switch type

Visi-Flex DE-ION

Trip type

Model A trip

Catalogs

[Eaton's Volume 2—Commercial Distribution](#)

Multimedia

[Single-phase disconnect and bypass switches](#)

Specifications and datasheets

[Eaton Specification Sheet - 2607D91G12](#)

Warranty guides

[Selling Policy 25-000 - Distribution and Control Products and Services](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)