

Eaton AN13PB

Catalog Number: AN13PB

NEMA A200 Thermal Overload Relay, Three-pole, Panel mounted, NEMA , Thermal Type A, Class 20, 1NC Auxiliary Contact, Alarm Contact (Form C) , Full load range .25-26.2A

General specifications

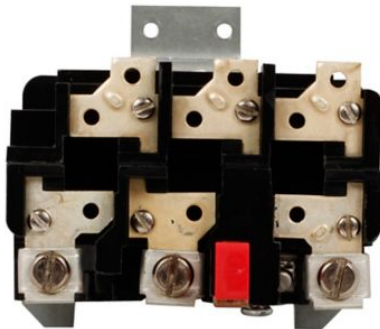


Photo is representative

Product Name

Eaton Freedom NEMA overload relay

Catalog Number

AN13PB

UPC

782114185551

Product Length/Depth

4.8 in

Product Height

3.4 in

Product Width

3.5 in

Product Weight

0.95 lb

Warranty

Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Certifications

UL Listed

CSA Certified

Catalog Notes

3-Pole Type B Overload Relay is a suitable alternative to a 3-Pole Type A Overload Relay in Manual Reset Mode

Modification

1NC Auxiliary Contact, Alarm Contact (Form C)

Design

NEMA

Full load current range

.25-26.2A

Mounting

Panel

Number Of Poles

Three-pole

Special features

Heaters required

Trip Type

Thermal Type A, Class 20

Type

A200

Catalogs

Eaton's Volume 5—Motor Control and Protection

Installation instructions

Instructions for A200, A210, A250 size 6, two- or three-pole non-reversing or reversing motor controllers

Specifications and datasheets

Eaton Specification Sheet - AN13PB



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



Eaton.com/socialmedia