

# Eaton AREA204225

Catalog Number: AREA204225

Eaton Crouse-Hinds series Arktite AREA receptacle assembly, 200A, Three-wire, four-pole, 50-400 Hz, Style 2, Copper-free aluminum, Spring door, Crimp/solder, 1-1/2", 600 Vac/250 Vdc, 0.75"

## General specifications

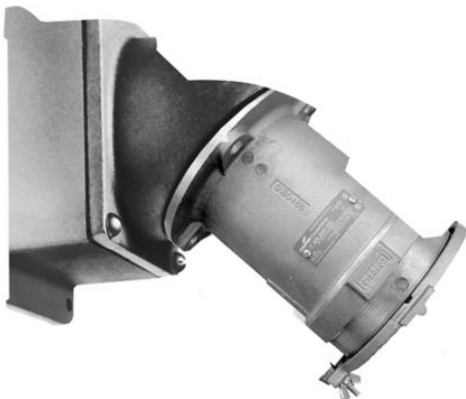


Photo is representative

Product Name	Catalog Number
Eaton Crouse-Hinds series Arktite AREA receptacle assembly	AREA204225
	UPC
	782274041803
Product Length/Depth	Product Height
15.63 in	14.44 in
Product Width	Product Weight
8.38 in	19.6 lb

## Certifications and compliances

### Area classification

Ordinary/Non-Hazardous Locations

### Standards type

NEC/CEC

### NEMA Rating

3R

## Product specifications

### Amperage Rating

200A

### Voltage rating

600 Vac/250 Vdc

### Frequency rating

50 to 400 Hz

### Grounding type

Style 2

### Configuration

Three-wire, four-pole

### Trade size

1-1/2"

### Receptacle style

Spring door

### Termination style

Crimp/solder

### Wire well size

0.75"

### Material

Copper-free aluminum

## Resources

### Catalogs

[Arkite 200A Metallic Plugs, Receptacles and Connectors catalog page](#)

### Installation instructions

[IF 352 - Model M72 Arkite Plugs and Receptacles](#)

[IF 853 - Arkite AR Series, Model 80 200A/400A](#)

### Specifications and datasheets

[Eaton Specification Sheet - AREA204225](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)