

Eaton AREA20427

Catalog Number: AREA20427

Eaton Crouse-Hinds series Arktite AREA receptacle assembly, 200A, Three-wire, four-pole, 50-400 Hz, Style 2, Copper-free aluminum, Spring door, Crimp/solder, 2-1/2", 600 Vac/250 Vdc, 0.56"

General specifications

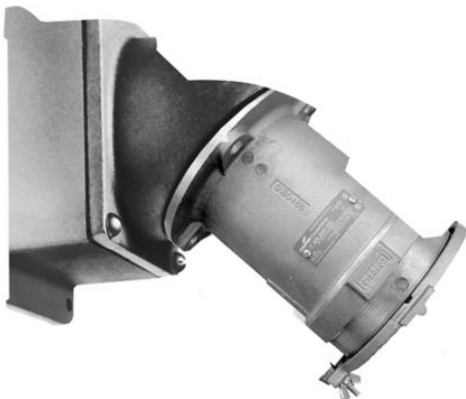


Photo is representative

Product Name	Catalog Number
Eaton Crouse-Hinds series Arktite AREA receptacle assembly	AREA20427
	UPC
	782274041513
Product Length/Depth	Product Height
15.63 in	14.44 in
Product Width	Product Weight
8.38 in	19.6 lb

Certifications and compliances

Area classification

Ordinary/Non-Hazardous Locations

Standards type

NEC/CEC

NEMA Rating

3R

Product specifications

Amperage Rating

200A

Voltage rating

600 Vac/250 Vdc

Frequency rating

50 to 400 Hz

Grounding type

Style 2

Configuration

Three-wire, four-pole

Trade size

2-1/2"

Receptacle style

Spring door

Termination style

Crimp/solder

Wire well size

0.56"

Material

Copper-free aluminum

Resources

Catalogs

[Arktime 200A Metallic Plugs, Receptacles and Connectors catalog page](#)

Installation instructions

[IF 352 - Model M72 Arktime Plugs and Receptacles](#)

[IF 853 - Arktime AR Series, Model 80 200A/400A](#)

Specifications and datasheets

[Eaton Specification Sheet - AREA20427](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)