

Eaton AREA6425

Catalog Number: AREA6425

Eaton Crouse-Hinds series Arktite AREA receptacle assembly, 60A, Three-wire, four-pole, 50-400 Hz, Style 2, Copper-free aluminum, Spring door, 1-1/2", 600 Vac/250 Vdc

General specifications

Product Name	Catalog Number
Eaton Crouse-Hinds series Arktite AREA receptacle assembly	AREA6425
	UPC
	782274034935
Product Length/Depth	Product Height
8.88 in	9.44 in
Product Width	Product Weight
5.88 in	7.1 lb

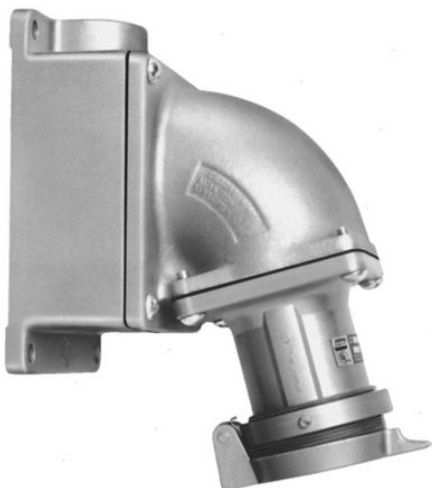


Photo is representative

Certifications and compliances

Area classification

Ordinary/Non-Hazardous Locations

Standards type

NEC/CEC

NEMA Rating

4

Product specifications

Amperage Rating

60A

Voltage rating

600 Vac/250 Vdc

Frequency rating

50 to 400 Hz

Grounding type

Style 2

Configuration

Three-wire, four-pole

Trade size

1-1/2"

Receptacle style

Spring door

Material

Copper-free aluminum

Resources

3D CAD drawing package

[Eaton Crouse-Hinds AREA6425 3D drawing](#)

Catalogs

[Arktime 60A Metallic Plugs, Receptacles and Connectors catalog page](#)

Installation instructions

[IF 352 - Model M72 Arktime Plugs and Receptacles](#)

Specifications and datasheets

[Eaton Specification Sheet - AREA6425](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are
property of their respective
owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)