


# Eaton ARES40317

Catalog Number: ARES40317

Eaton Crouse-Hinds series Arktite ARES receptacle assembly, 400A, Three-wire, three-pole, 50-400 Hz, Style 1, Copper-free aluminum, Spring door, 2-1/2", 600 Vac/250 Vdc, 0.84"

## General specifications

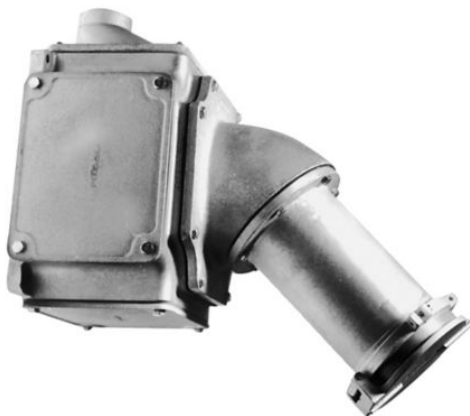

Product Name	Catalog Number
Eaton Crouse-Hinds series Arktite ARES receptacle assembly	ARES40317
	UPC 662276183414
Product Length/Depth	Product Height
23.63 in	19.31 in
Product Width	Product Weight
13 in	61.6 lb

Photo is representative

## Certifications and compliances

### Area classification

Ordinary/Non-Hazardous Locations

### Standards type

NEC/CEC

## Product specifications

### Amperage Rating

400A

### Voltage rating

600 Vac/250 Vdc

### Frequency rating

50 to 400 Hz

### Grounding type

Style 1

### Configuration

Three-wire, three-pole

### Trade size

2-1/2"

### Receptacle style

Spring door

### Wire well size

0.84"

### Material

Copper-free aluminum

## Resources

### 3D CAD drawing package

[Eaton Crouse-Hinds AREX40317 3D drawing](#)

### Catalogs

[Arktite 400A Metallic Plugs, Receptacles and Connectors catalog page](#)

### Installation instructions

[IF 352 - Model M72 Arktite Plugs and Receptacles](#)

[IF 853 - Arktite AR Series, Model 80 200A/400A](#)

### Specifications and datasheets

[Eaton Specification Sheet - AREX40317](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)