


Eaton ARES403229

Catalog Number: ARES403229

Eaton Crouse-Hinds series Arktite ARES receptacle assembly, 400A, Two-wire, three-pole, 50-400 Hz, Style 2, Copper-free aluminum, Spring door, 3-1/2", 600 Vac/250 Vdc, 1.25"

General specifications

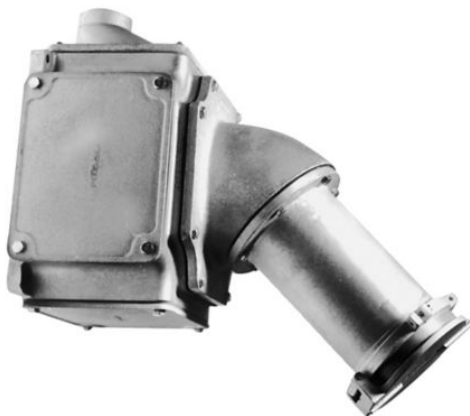

Product Name	Catalog Number
Eaton Crouse-Hinds series Arktite ARES receptacle assembly	ARES403229
	UPC 662276185739
Product Length/Depth	Product Height
23.63 in	19.31 in
Product Width	Product Weight
13 in	61.6 lb

Photo is representative

Certifications and compliances

Area classification

Ordinary/Non-Hazardous Locations

Standards type

NEC/CEC

Product specifications

Amperage Rating

400A

Voltage rating

600 Vac/250 Vdc

Frequency rating

50 to 400 Hz

Grounding type

Style 2

Configuration

Two-wire, three-pole

Trade size

3-1/2"

Receptacle style

Spring door

Wire well size

1.25"

Material

Copper-free aluminum

Resources

3D CAD drawing package

[Eaton Crouse-Hinds AREX403229 3D drawing](#)

Catalogs

[Arktite 400A Metallic Plugs, Receptacles and Connectors catalog page](#)

Installation instructions

[IF 853 - Arktite AR Series, Model 80 200A/400A](#)

[IF 352 - Model M72 Arktite Plugs and Receptacles](#)

Specifications and datasheets

[Eaton Specification Sheet - AREX403229](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)