

# Eaton BA13JPX

Catalog Number: BA13JPX

NEMA A200 Thermal Overload Relay, Three-pole, Panel mounted, NEMA , Thermal Type B, Class 20, 1NC Auxiliary Contact, Ambient Compensated , Full load range .25-26.2A, X

## General specifications

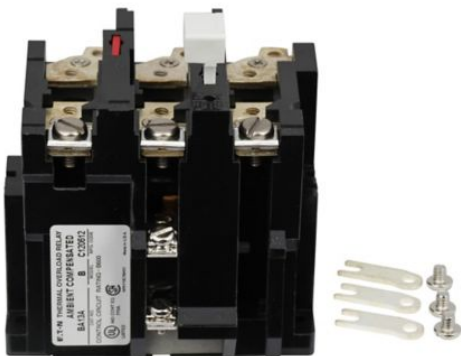


Photo is representative

### Product Name

Eaton Freedom NEMA overload relay

### Catalog Number

BA13JPX

### UPC

782114796122

### Product Length/Depth

5 in

### Product Height

3.4 in

### Product Width

3.6 in

### Product Weight

0.9 lb

### Warranty

Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

### Certifications

UL Listed

CSA Certified

Modification

1NC Auxiliary Contact, Ambient Compensated

Design

NEMA

Full load current range

.25-26.2A

Mounting

Panel

Number Of Poles

Three-pole

Special features

Heaters required

Trip Type

Thermal Type B, Class 20

Type

A200

Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

Specifications and datasheets

[Eaton Specification Sheet - BA13JPX](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)