

Eaton C361FSC161

Catalog Number: C361FSC161

Type C361 Flange Mounted Disconnect Switch, Switch and operating mechanism with handle, 4 in handle, #2-14 AWG Cu/Al, NEMA 1 or 12 enclosure, Right-hand mounting, 7.5 hp at 208 Vac fuse clip rating, 30A, 6.5 in minimum depth

General specifications

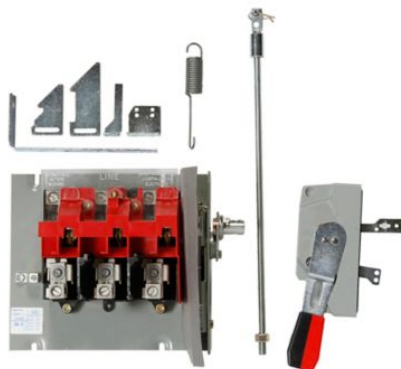


Photo is representative

Product Name

Eaton rotary disconnect main switch

UPC

782113782522

Product Height

8.63 in

Product Weight

19 lb

Certifications

UL Listed
CSA Certified

Catalog Number

C361FSC161

Product Length/Depth

11.38 in

Product Width

6.5 in

Warranty

1 year

Catalog Notes

Maximum horsepower ratings refer to switch only. Fuse clips are non-interchangeable type for Class H, J, K, or R type fuses only.

Physical Attributes

Enclosure

NEMA 1, NEMA 12

Handle Length

4 in

Mounting

Right

Type

Switch and operating mechanism with handle

Wire size

#14-2 AWG Cu/Al

Performance Ratings

Amperage Rating

30A

Depth range

6.5 in minimum

Fuse clip rating

60 A at 250 V, 30 A at 600 V

HP rating - max

7.5 hp at 208 Vac, 7.5 hp at 240 Vac, 15 hp at 480 Vac, 20 hp at 600 Vac, 5 hp at 250 Vdc

Resources

Catalogs

[Eaton's Volume 2—Commercial Distribution](#)

Multimedia

[Switching Devices Flex Center](#)

Specifications and datasheets

[Eaton Specification Sheet - C361FSC161](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)