

Eaton C361FSC161R

Catalog Number: C361FSC161R

Type C361 Flange Mounted Disconnect Switch, Switch and operating mechanism with handle, 4 in handle, Rejection Clips, #2-14 AWG Cu/Al, NEMA 1 or 12 enclosure, Right-hand mounting, 30A, 6.5 in minimum depth

General specifications

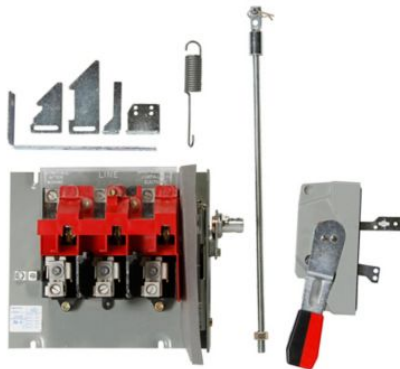


Photo is representative

Product Name

Eaton rotary disconnect main switch

Catalog Number

C361FSC161R

UPC

782113910604

Product Length/Depth

11.38 in

Product Height

8.63 in

Product Width

6.5 in

Product Weight

0.001 lb

Warranty

1 year

Certifications

UL Listed
CSA Certified

Catalog Notes

Maximum horsepower ratings refer to switch only. Fuse clips are non-interchangeable type for Class H, J, K, or R type fuses only.

Physical Attributes

Enclosure

NEMA 1, NEMA 12

Handle Length

4 in

Mounting

Right

Type

Switch and operating mechanism with handle

Wire size

#14-2 AWG Cu/Al

Performance Ratings

Amperage Rating

30A

Depth range

6.5 in minimum

Fuse clip rating

60 A at 250 V, 30 A at 600 V

HP rating - max

7.5 hp at 208 Vac, 7.5 hp at 240 Vac, 15 hp at 480 Vac, 20 hp at 600 Vac, 5 hp at 250 Vdc

Miscellaneous

Accessories

Rejection clips

Resources

Catalogs

[Eaton's Volume 2—Commercial Distribution](#)

Multimedia

[Switching Devices Flex Center](#)

Specifications and datasheets

[Eaton Specification Sheet - C361FSC161R](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)