

Eaton C361NC2

Catalog Number: C361NC2

Type C361 Flange Mounted DS, Switch and operating mechanism with handle, 4 in handle, #2-14 AWG Cu/Al, NEMA 4 enclosure, Right-hand MTG, 7.5 hp at 208 Vac, 7.5 hp at 240 Vac, Non-fusible, 30A, 7-16 in depth

General specifications

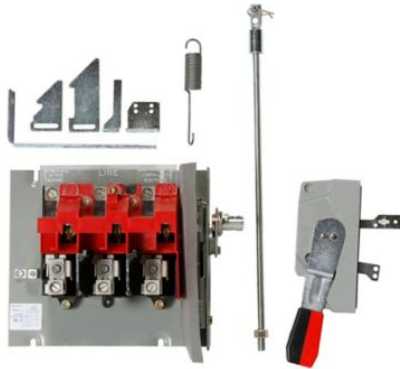


Photo is representative

Product Name	Catalog Number
Eaton rotary disconnect main switch	C361NC2
UPC	Product Length/Depth
782113566047	19.18799973 in
Product Height	Product Width
9.875 in	11.5 in
Product Weight	Warranty
0.001 lb	1 year
Certifications	Catalog Notes
CSA Certified UL Listed	Maximum horsepower ratings refer to switch only

Physical Attributes

Enclosure

NEMA 4

Handle Length

4 in

Mounting

Right

Type

Switch and operating mechanism with handle

Wire size

#14-2 AWG Cu/Al

Performance Ratings

Amperage Rating

30A

Depth range

7-16 in

Fuse clip rating

Non-fusible

HP rating - max

7.5 hp at 208 Vac, 7.5 hp at 240 Vac, 15 hp at 480 Vac, 20 hp at 600 Vac, 5 hp at 250 Vdc

Resources

Catalogs

[Eaton's Volume 2—Commercial Distribution](#)

Multimedia

[Switching Devices Flex Center](#)

Specifications and datasheets

[Eaton Specification Sheet - C361NC2](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)