

# Eaton C361ND1

Catalog Number: C361ND1

Type C361 Flange Mounted DS, Switch and operating mechanism with handle, 4 in handle, #2-14 AWG Cu/Al, NEMA 1 or 12 enclosure, Right-hand MTG, 15 hp at 208 Vac, Non-fusible, 60A, 7-16 in depth

## General specifications

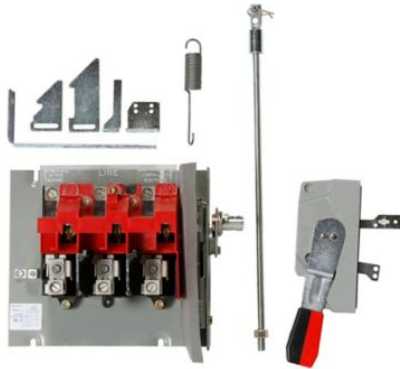


Photo is representative

<b>Product Name</b>	<b>Catalog Number</b>
Eaton rotary disconnect main switch	C361ND1
<b>UPC</b>	<b>Product Length/Depth</b>
782113566078	19.188 in
<b>Product Height</b>	<b>Product Width</b>
9.875 in	11.5 in
<b>Product Weight</b>	<b>Warranty</b>
7.2 lb	1 year
<b>Certifications</b>	<b>Catalog Notes</b>
CSA Certified UL Listed	Maximum horsepower ratings refer to switch only

## Physical Attributes

### Enclosure

NEMA 1, NEMA 12

### Handle Length

4 in

### Mounting

Right

### Type

Switch and operating mechanism with handle

### Wire size

#14-2 AWG Cu/Al

## Performance Ratings

### Amperage Rating

60A

### Depth range

7-16 in

### Fuse clip rating

Non-fusible

### HP rating - max

15 hp at 208 Vac, 15 hp at 240 Vac, 30 hp at 480 Vac, 50 hp at 600 Vac, 10 hp at 250 Vdc

## Resources

### Catalogs

[Eaton's Volume 2—Commercial Distribution](#)

### Multimedia

[Switching Devices Flex Center](#)

### Specifications and datasheets

[Eaton Specification Sheet - C361ND1](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)