

# Eaton C361SC161R

Catalog Number: C361SC161R

Type C361 Flange Mounted Disconnect Switch, Switch and operating mechanism with handle, 4 in handle, Rejection Clips, #2-14 AWG Cu/Al, NEMA 1 or 12 enclosure, Right-hand mounting, 30A, 7-16 in depth

## General specifications

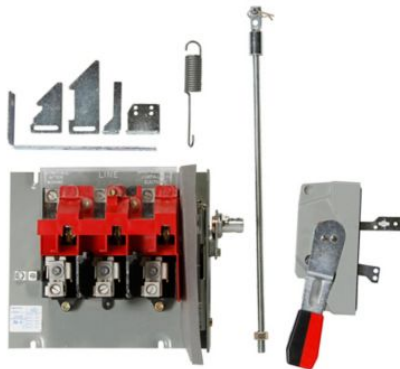


Photo is representative

### Product Name

Eaton rotary disconnect main switch

### Catalog Number

C361SC161R

### UPC

782113924229

### Product Length/Depth

19.188 in

### Product Height

9.875 in

### Product Width

11.5 in

### Product Weight

0.001 lb

### Warranty

1 year

### Certifications

CSA Certified

UL Listed

### Catalog Notes

Maximum horsepower ratings refer to switch only. Fuse clips are non-interchangeable type for Class H, J, K, or R type fuses only. Components individually boxed and shipped in overpack carton.

## Physical Attributes

### Enclosure

NEMA 1, NEMA 12

### Handle Length

4 in

### Mounting

Right

### Type

Switch and operating mechanism with handle

### Wire size

#14-2 AWG Cu/Al

## Performance Ratings

### Amperage Rating

30A

### Depth range

7-16 in

### Fuse clip rating

60 A at 250 V, 30 A at 600 V

### HP rating - max

7.5 hp at 208 Vac, 7.5 hp at 240 Vac, 15 hp at 480 Vac, 20 hp at 600 Vac, 5 hp at 250 Vdc

## Miscellaneous

### Accessories

Rejection clips

## Resources

### Catalogs

[Eaton's Volume 2—Commercial Distribution](#)

### Multimedia

[Switching Devices Flex Center](#)

### Specifications and datasheets

[Eaton Specification Sheet - C361SC161R](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com

© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)