


# Eaton C361SE263

Catalog Number: C361SE263

Type C361 Flange Mounted DS, Switch and operating mechanism only, #1/0-14 AWG Cu/Al, Right-hand MTG, 25 hp at 208 Vac, 30 hp at 240 Vac, 60 hp at 480 Vac, 75 hp at 600 Vac, 20 hp at 250 Vdc, 100A at 250/600V fuse clip rating, 100A

## General specifications

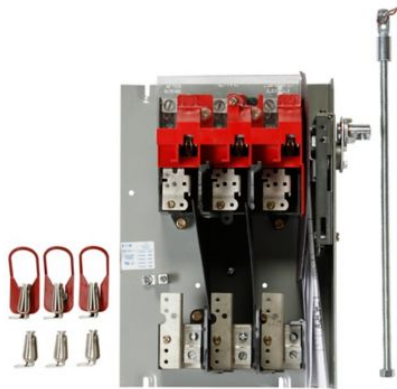

### Product Name

Eaton rotary disconnect main switch

### UPC

782113599472

### Product Height

8.5 in

### Product Weight

11.2 lb

### Certifications

UL Listed  
CSA Certified

### Catalog Number

C361SE263

### Product Length/Depth

14.4 in

### Product Width

12 in

### Warranty

1 year

### Catalog Notes

Maximum horsepower ratings refer to switch only. Fuse clips are non-interchangeable type for Class H, J, K, or R type fuses only. DOES NOT include handle, must be purchased separately.

## Physical Attributes

### Mounting

Right

### Type

Switch and operating mechanism only

### Wire size

#14-1/0 AWG Cu/Al

## Performance Ratings

### Amperage Rating

100A

### Depth range

7-16 in

### Fuse clip rating

100 A at 250/600 V

### HP rating - max

25 hp at 208 Vac, 30 hp at 240 Vac, 60 hp at 480 Vac, 75 hp at 600 Vac, 20 hp at 250 Vdc

## Resources

### Catalogs

[Eaton's Volume 2—Commercial Distribution](#)

### Multimedia

[Switching Devices Flex Center](#)

### Specifications and datasheets

[Eaton Specification Sheet - C361SE263](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)