

Eaton C65DNJ350T

Catalog Number: C65DNJ350T

Eaton definite purpose contactor, Quick, 50A, 24 Vac, 50/60 Hz, Mounting plate, 15-50A, two- and three-pole, 50A, Contactor, Three-pole, 65A, Box lugs (posidrive setscrew) and quick connect terminals (vertical-in-line), Reversing

General specifications

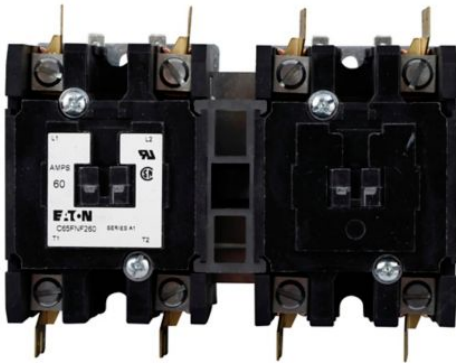


Photo is representative

Product Name	Catalog Number
Eaton definite purpose contactor	C65DNJ350T
UPC	Product Length/Depth
782116366224	3.35 in
Product Height	Product Width
3.75 in	5 in
Product Weight	Warranty
2.6 lb	1 year
Compliances	Certifications
RoHS Compliant	UL Recognized CSA Certified

defaultTaxonomyAttributeLabel

Amperage Rating

50A

Number Of Poles

Three-pole

Type

Reversing

Coil

24 Vac, 50/60 Hz

Enclosure

Open with metal mounting plate

Frame size

15-50 A, two-pole and three-pole

Inductive full load

50 A

Model

Contactor

Resistive load

65 A

Terminals

Box lugs (posidrive setscrew) and quick connect terminals
(vertical-in-line)

Connection

Quick

Resources

Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

Drawings

[C65DNJ3 AutoCAD 2D Footprint \(mm\)](#)

[C65DNJ3 2D PDF](#)

[C65DNJ3 3D Model Xchange](#)

[C65DNJ3 3D Inventor](#)

[C65DNJ3 AutoCAD 2D Footprint](#)

[C65DNJ3 2D Drawing Xchange](#)

Specifications and datasheets

[Eaton Specification Sheet - C65DNJ350T](#)