

Eaton C65DRC315T

Catalog Number: C65DRC315T

Eaton definite purpose contactor, Quick, 15A, 24 Vac, 50/60 Hz, Open with DIN rail mounting adapter, 15-50A, two- and three-pole, 15A, Contactor, Three-pole, 15A, Screw/pressure plate, Reversing

General specifications

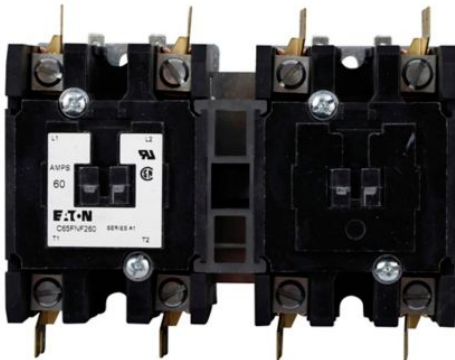


Photo is representative

| | |
|----------------------------------|-----------------------------|
| Product Name | Catalog Number |
| Eaton definite purpose contactor | C65DRC315T |
| UPC | Product Length/Depth |
| 782116483532 | 3.35 in |
| Product Height | Product Width |
| 3.75 in | 5 in |
| Product Weight | Warranty |
| 2.6 lb | 1 year |
| Compliances | Certifications |
| RoHS Compliant | UL Recognized |
| | CSA Certified |

Amperage Rating

15A

Number Of Poles

Three-pole

Type

Reversing

Coil

24 Vac, 50/60 Hz

Enclosure

Open with DIN rail mounting adapter

Frame size

15-50 A, two-pole and three-pole

Inductive full load

15 A

Model

Contactor

Resistive load

20 A

Terminals

Screw/pressure plate

Connection

Quick

Catalogs[Eaton's Volume 5—Motor Control and Protection](#)**Specifications and datasheets**[Eaton Specification Sheet - C65DRC315T](#)