

Eaton C65DRC3251T

Catalog Number: C65DRC3251T

Eaton definite purpose contactor, Quick, 25A, 24 Vdc, Open with DIN rail mounting adapter, 15-50A, two- and three-pole, 25A, Contactor, Three-pole, 35A, Screw/pressure plate, Reversing

General specifications

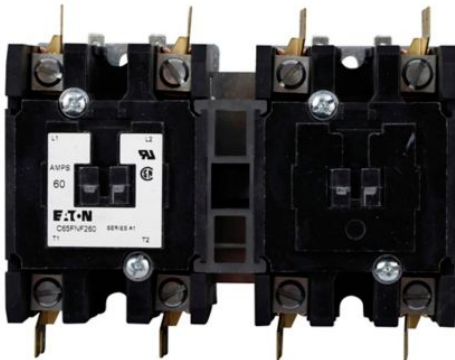


Photo is representative

Product Name	Catalog Number
Eaton definite purpose contactor	C65DRC3251T
UPC	Product Length/Depth
782116483662	3.35 in
Product Height	Product Width
3.75 in	5 in
Product Weight	Warranty
2.6 lb	1 year
Compliances	Certifications
RoHS Compliant	UL Recognized
	CSA Certified

Amperage Rating

25A

Number Of Poles

Three-pole

Type

Reversing

Coil

24 Vdc

Enclosure

Open with DIN rail mounting adapter

Frame size

15-50 A, two-pole and three-pole

Inductive full load

25 A

Model

Contactor

Resistive load

35 A

Terminals

Screw/pressure plate

Connection

Quick

Catalogs[Eaton's Volume 5—Motor Control and Protection](#)**Specifications and datasheets**[Eaton Specification Sheet - C65DRC3251T](#)