

# Eaton C65DRD230A

Catalog Number: C65DRD230A

Eaton definite purpose contactor, Quick, 30A, 110-120 Vac, 50/60 Hz, Open with DIN rail mounting adapter, 15-50A, two- and three-pole, 30A, Contactor, Two-pole, 40A, Screw/pressure plate and quick connect terminals (side-by-side), Reversing

## General specifications

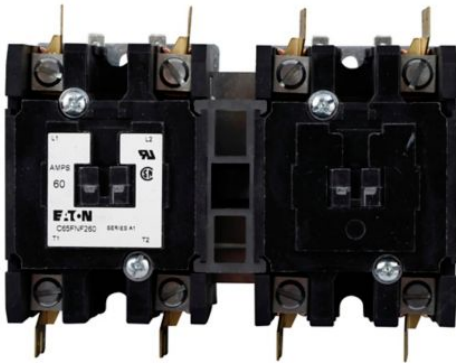


Photo is representative

<b>Product Name</b>	<b>Catalog Number</b>
Eaton definite purpose contactor	C65DRD230A
<b>UPC</b>	<b>Product Length/Depth</b>
782116483075	3.35 in
<b>Product Height</b>	<b>Product Width</b>
3.75 in	5 in
<b>Product Weight</b>	<b>Warranty</b>
2.6 lb	1 year
<b>Compliances</b>	<b>Certifications</b>
RoHS Compliant	UL Recognized CSA Certified

## defaultTaxonomyAttributeLabel

### Amperage Rating

30A

### Number Of Poles

Two-pole

### Type

Reversing

### Coil

110-120 Vac, 50/60 Hz

### Enclosure

Open with DIN rail mounting adapter

### Frame size

15-50 A, two-pole and three-pole

### Inductive full load

30 A

### Model

Contacto

### Resistive load

40 A

### Terminals

Screw/pressure plate and quick connect terminals (side-by-side)

### Connection

Quick

## Resources

### Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

### Drawings

[C65DRD2 AutoCAD 2D Footprint \(mm\)](#)

[C65DRD2 2D Drawing Xchange](#)

[C65DRD2 3D Inventor](#)

[C65DRD2 3D Model Xchange](#)

[C65DRD2 AutoCAD 2D Footprint](#)

[C65DRD2 2D PDF](#)

### Specifications and datasheets

[Eaton Specification Sheet - C65DRD230A](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com

© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)