


Eaton C65DRD315B

Catalog Number: C65DRD315B

Eaton definite purpose contactor, Quick, 15A, 208-240 Vac, 50/60 Hz, Open with DIN rail mounting adapter, 15-50A, two- and three-pole, 15A, Contactor, Three-pole, 20A, Screw/pressure plate and quick connect terminals (side-by-side), Reversing

General specifications

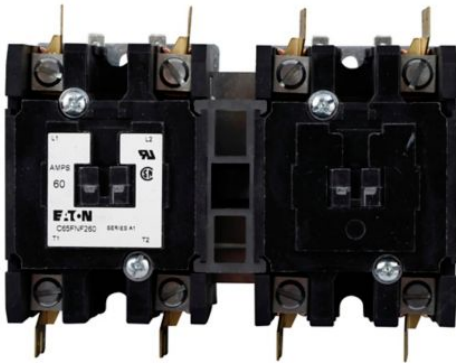

Product Name	Catalog Number
Eaton definite purpose contactor	C65DRD315B
UPC	Product Length/Depth
782116483563	3.35 in
Product Height	Product Width
3.75 in	5 in
Product Weight	Warranty
2.6 lb	1 year
Compliances	Certifications
RoHS Compliant	CSA Certified UL Recognized

defaultTaxonomyAttributeLabel

Amperage Rating

15A

Number Of Poles

Three-pole

Type

Reversing

Coil

208-240 Vac, 50/60 Hz

Enclosure

Open with DIN rail mounting adapter

Frame size

15-50 A, two-pole and three-pole

Inductive full load

15 A

Model

Contactors

Resistive load

20 A

Terminals

Screw/pressure plate and quick connect terminals (side-by-side)

Connection

Quick

Resources

Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

Drawings

[C65DRD3 AutoCAD 2D Footprint \(mm\)](#)

[C65DRD3 3D Model Xchange](#)

[C65DRD3 2D Drawing Xchange](#)

[C65DRD3 3D Inventor](#)

[C65DRD3 AutoCAD 2D Footprint](#)

[C65DRD3 2D PDF](#)

Specifications and datasheets

[Eaton Specification Sheet - C65DRD315B](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)