

Eaton C65DRD330A

Catalog Number: C65DRD330A

Eaton definite purpose contactor, Quick, 30A, 110-120 Vac, 50/60 Hz, Open with DIN rail mounting adapter, 15-50A, two and three pole, Contactor, Three-pole, 40A, Screw/pressure plate and quick connect terminals (side-by-side), Reversing

General specifications

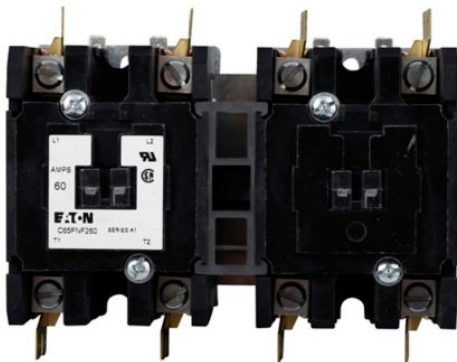


Photo is representative

Product Name	Catalog Number
Eaton definite purpose contactor	C65DRD330A
UPC	Product Length/Depth
782116483877	3.35 in
Product Height	Product Width
3.75 in	5 in
Product Weight	Warranty
2.6 lb	1 year
Compliances	Certifications
RoHS Compliant	CSA Certified
	UL Recognized

defaultTaxonomyAttributeLabel

Amperage Rating

30A

Number Of Poles

Three-pole

Type

Reversing

Coil

110-120 Vac, 50/60 Hz

Enclosure

Open with DIN rail mounting adapter

Frame size

15-50 A, two-pole and three-pole

Inductive full load

30 A

Model

Contactors

Resistive load

40 A

Terminals

Screw/pressure plate and quick connect terminals (side-by-side)

Connection

Quick

Resources

Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

Drawings

[C65DRD3 3D Model Xchange](#)

[C65DRD3 2D Drawing Xchange](#)

[C65DRD3 AutoCAD 2D Footprint \(mm\)](#)

[C65DRD3 3D Inventor](#)

[C65DRD3 AutoCAD 2D Footprint](#)

[C65DRD3 2D PDF](#)

Specifications and datasheets

[Eaton Specification Sheet - C65DRD330A](#)