

Eaton C65DRJ250B

Catalog Number: C65DRJ250B

Eaton definite purpose contactor, Quick, 50A, 208-240 Vac, 50/60 Hz, Open with DIN rail mounting adapter, 15-50A, two- and three-pole, 50A, Contactor, Two-pole, 65A, Box lugs (posidrive setscrew) and quick connect terminals, Reversing

General specifications

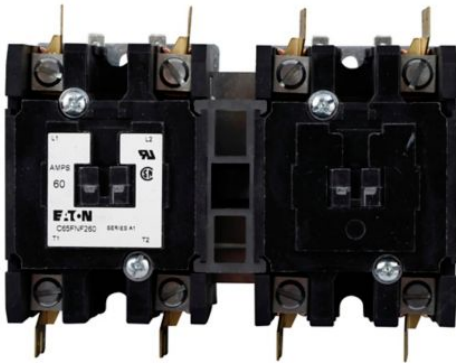


Photo is representative

Product Name	Catalog Number
Eaton definite purpose contactor	C65DRJ250B
UPC	Product Length/Depth
782116483402	3.35 in
Product Height	Product Width
3.75 in	5 in
Product Weight	Warranty
2.6 lb	1 year
Compliances	Certifications
RoHS Compliant	UL Recognized CSA Certified

defaultTaxonomyAttributeLabel

Amperage Rating

50A

Number Of Poles

Two-pole

Type

Reversing

Coil

208-240 Vac, 50/60 Hz

Enclosure

Open with DIN rail mounting adapter

Frame size

15-50 A, two-pole and three-pole

Inductive full load

50 A

Model

Contactors

Resistive load

65 A

Terminals

Box lugs (posidrive setscrew) and quick connect terminals
(vertical-in-line)

Connection

Quick

Resources

Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

Drawings

[C65DRJ2 AutoCAD 2D Footprint \(mm\)](#)

[C65DRJ2 3D Model Xchange](#)

[C65DRJ2 2D Drawing Xchange](#)

[C65DRJ2 3D Inventor](#)

[C65DRJ2 AutoCAD 2D Footprint](#)

[C65DRJ2 2D PDF](#)

Specifications and datasheets

[Eaton Specification Sheet - C65DRJ250B](#)