

Eaton C65FNF275B

Catalog Number: C65FNF275B

Eaton definite purpose contactor, Quick, 60A, 110-120 Vac, 50/60 Hz, Open with metal mounting plate, 15-50A, two- and three-pole, 60A, Contactor, Two-pole, 75A, Box lugs (posidrive setscrew) and quick connect terminals , Reversing

General specifications

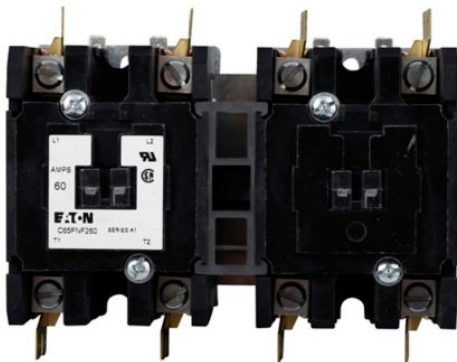


Photo is representative

Product Name	Catalog Number
Eaton definite purpose contactor	C65FNF275B
UPC	Product Length/Depth
782114621417	3.97 in
Product Height	Product Width
3.75 in	5.77 in
Product Weight	Warranty
2.6 lb	1 year
Compliances	Certifications
RoHS Compliant	CSA Certified UL Recognized
Catalog Notes	
Resistive Load rating per pole	

defaultTaxonomyAttributeLabel

Amperage Rating

35A

Number Of Poles

Three-pole

Type

DPCK

Coil

208/240 Vac, 50/60 Hz

Enclosure

Open with metal mounting plate

Frame size

60-75 A, two-pole and three-pole

Inductive full load

35 A

Model

Contactors

Resistive load

35 A, 600 V

Terminals

Box lugs (posidrive setscrew) and quick connect terminals (side-by-side)

Connection

Quick

Resources

Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

Drawings

[C65FNF2 2D PDF](#)

[C65FNF2 2D Drawing Xchange](#)

[C65FNF2 AutoCAD 2D Footprint \(mm\)](#)

[C65FNF2 3D Inventor](#)

[C65FNF2 3D Model Xchange](#)

[C65FNF2 AutoCAD 2D Footprint](#)

Specifications and datasheets

[Eaton Specification Sheet - C65FNF275B](#)