

Eaton DILM115-22(RAC120)

Catalog Number: DILM115-22(RAC120)

Eaton XT IEC contactor, 115A, 120 Vdc, 2NO-2NC, 115A, Frame G, 90 mm, 10, 25/40, 50, 100, 100 (1/3PH @ 120, 240/208, 240, 480, 600 V), Three-pole, Non-reversing, XT IEC series, Screw terminals, Full voltage non-reversing contactor, 55 kW

General specifications

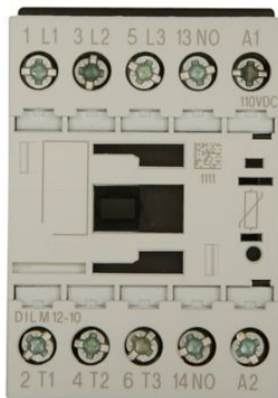


Photo is representative

Product Name

Eaton XT IEC contactor

EAN

4015082395773

Product Height

6.7 in

Product Weight

5.3 lb

Compliances

CE Marked

RoHS Compliant

Catalog Number

DILM115-22(RAC120)

Product Length/Depth

3.5 in

Product Width

6.9 in

Warranty

1 year

Certifications

EN 60947

CSA Certified

IEC 60947

UL Listed

Catalog Notes

Screw terminals (6-65A); 5 mm(80-150A); no lugs (185-2000A).

defaultTaxonomyAttributeLabel

Amperage Rating

115A

HP rating - max

10, 25/40,50,100,100 (1/3PH @120,240/208,240,480,600 V)

Number Of Poles

Three-pole

Type

Full voltage non-reversing contactor

Frame size

90 mm

Terminals

Screw terminals

Coil

120 Vdc

Coil voltage

120 Vdc

Contact configuration

2 NO, 2 NC

Continuous ampere rating

115 A

Series

XT IEC

Operation

Non-reversing

Power consumption

55 kW

Resources

Specifications and datasheets

[Global Data Sheet - DILM115-22\(RAC120\)](#)

[Eaton Specification Sheet - DILM115-22\(RAC120\)](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)