

# Eaton DILM115-22(RAC240)

Catalog Number: DILM115-22(RAC240)

Eaton XT IEC contactor, 115A, 240 Vdc, 2NO-2NC, 115A, Frame G, 90 mm, 10, 25/40, 50, 100, 100 (1/3PH @ 120, 240/208, 240, 480, 600 V), Three-pole, Non-reversing, XT IEC series, Screw terminals, Full voltage non-reversing contactor, 55 kW

## General specifications

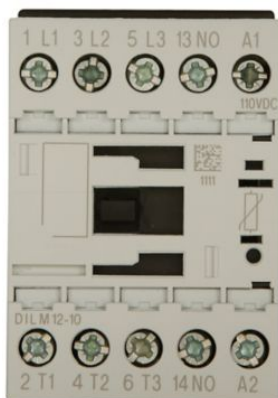


Photo is representative

### Product Name

Eaton XT IEC contactor

### EAN

4015082395780

### Product Height

6.7 in

### Product Weight

5.29 lb

### Compliances

CE Marked

RoHS Compliant

### Catalog Number

DILM115-22(RAC240)

### Product Length/Depth

3.5 in

### Product Width

6.9 in

### Warranty

1 year

### Certifications

EN 60947

UL Listed

CSA Certified

IEC 60947

### Catalog Notes

Screw terminals (6-65A); 5 mm(80-150A); no lugs (185-2000A).

## defaultTaxonomyAttributeLabel

### Amperage Rating

115A

### HP rating - max

10, 25/40,50,100,100 (1/3PH @120,240/208,240,480,600 V)

### Number Of Poles

Three-pole

### Type

Full voltage non-reversing contactor

### Frame size

90 mm

### Terminals

Screw terminals

### Coil

240 Vdc

### Coil voltage

240 Vdc

### Contact configuration

2 NO, 2 NC

### Continuous ampere rating

115 A

### Series

XT IEC

### Operation

Non-reversing

### Power consumption

55 kW

## Resources

### Specifications and datasheets

[Eaton Specification Sheet - DILM115-22\(RAC240\)](#)

[Global Data Sheet - DILM115-22\(RAC240\)](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)