

Eaton DILMC40(RDC24)

Catalog Number: DILMC40(RDC24)

Eaton XT IEC contactor, 40A, 24 Vdc, 4NO, 40A, Frame D, 55 mm, 3, 7.5/ 10, 15, 30, 40 (1/3PH @ 120, 240/208, 240, 480, 600 V), Three-pole, Non-reversing, XT IEC series, Spring cage terminals, Full voltage non-reversing contactor, 18.5 kW

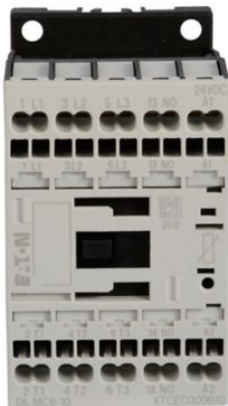


Photo is representative

General specifications

Product Name	Catalog Number
Eaton XT IEC contactor	DILMC40(RDC24)
EAN	Product Length/Depth
4015082779795	2.2 in
Product Height	Product Width
4.5 in	5.2 in
Product Weight	Warranty
2.42 lb	1 year
Compliances	Certifications
CE Marked	EN 60947
RoHS Compliant	CSA Certified
	UL Listed
	IEC 60947

Catalog Notes

Consult local sales office for availability.

defaultTaxonomyAttributeLabel

Amperage Rating

40A

HP rating - max

3, 7.5/ 10, 15, 30, 40 (1/3PH @120,240/208,240,480,600 V)

Number Of Poles

Three-pole

Type

Full voltage non-reversing contactor

Frame size

55 mm

Terminals

Spring cage terminals

Coil

24 Vdc

Coil voltage

24 Vdc

Contact configuration

4 NO

Continuous ampere rating

40 A

Series

XT IEC

Operation

Non-reversing

Power consumption

18.5 kW

Resources

Specifications and datasheets

[Eaton Specification Sheet - DILMC40\(RDC24\)](#)

[Global Data Sheet - DILMC40\(RDC24\)](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)