

Eaton HT8CFB

Catalog Number: HT8CFB

Eaton HT800 pushbutton, 30.5 mm, Watertight/Oiltight-HT800, Pushbutton, 40 mm, NEMA 1, 2, 3, 3R, 4, 4X, 12, Non-illuminated, Three-position, Maintained push, momentary pull, Blue actuator, Mushroom , Plastic, Chrome bezel

General specifications

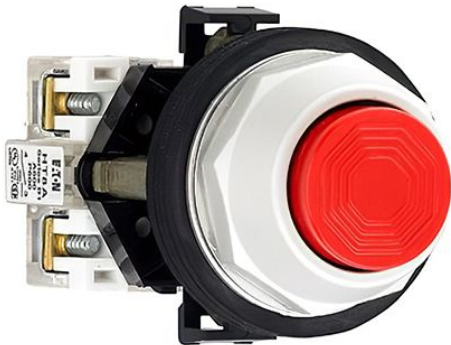


Photo is representative

Product Name	Catalog Number
Eaton HT800 pushbutton	HT8CFB
UPC	Product Length/Depth
782113682426	2.094 in
Product Height	Product Width
5.051 in	2.375 in
Product Weight	Warranty
1 lb	1 year
Compliances	Certifications
CE Marked	UL Listed CSA Certified

defaultTaxonomyAttributeLabel

Type

Push-Pull

Actuator color

Blue

Bezel

Chrome

Bus material

Anodized aluminum

Enclosure

NEMA 4X

NEMA 2

NEMA 12

NEMA 1

NEMA 3

NEMA 4

NEMA 3R

Actuator material

Plastic

Actuator

Mushroom

Operating mode

Pull: momentary

Push: maintained

Illumination

Non-illuminated

Series

HT800

Number of positions

3

Degree of protection

NEMA 12

NEMA 13

NEMA 4

NEMA 3

NEMA 3R

NEMA 4X

Product category

Resources

Brochures

Pushbuttons and Indicating Lights

HT800 30.5 mm pilot devices

Multimedia

How to size and select a Power Supply

Specifications and datasheets

Quick Selector - HT800 Pilot Devices

Eaton Specification Sheet - HT8CFB

Pushbutton

Size

40 mm



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)