

Eaton SB5866140UTG

Catalog Number: SB5866140UTG

Eaton B-Line series open frame racks, 340 lb load cap., Steel, Telco gray powder coat, 12-24 panel mounting holes, Anchor plates, shims and anchors included, 77 mounting spaces, Top angle style, Seismic Zone 4, network bay open duct rack

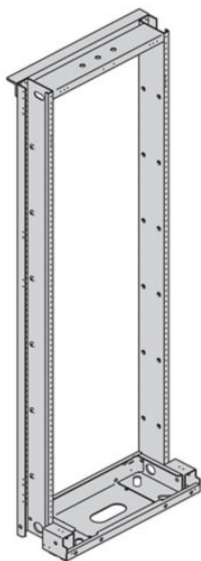


Photo is representative

General specifications

Product Name	Catalog Number
Eaton B-Line series open frame racks	SB5866140UTG
UPC	Product Length/Depth
799038289692	140 in
Product Height	Product Width
140 in	23 in
Product Weight	Certifications
158.89 lb	UL Listed

defaultTaxonomyAttributeLabel

Material

Steel

Mounting rails

12-24 panel mounting holes

Special features

77 mounting spaces

Surface finish

Telco gray powder coat

Type

Seismic Zone 4, network bay open duct rack

Cover/door type

Double sided

Load capacity

340 lb

Style

Top angle

Resources

Brochures

[RCM and RCM+ brochure](#)

Specifications and datasheets

[Eaton Specification Sheet - SB5866140UTG](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)