


Eaton TRAFGF20GY

Catalog Number: TRAFGF20GY

Eaton AFGF receptacle, Tamper resistant, Self-test, #14 - 10 AWG, 20A, Residential, Commercial, Flush, 125 V, AFGF, Back and side wire, Gray, Brass, Receptacle, Tamper resistant, Polycarbonate, 5-20R, Two-pole, three-wire, grounding

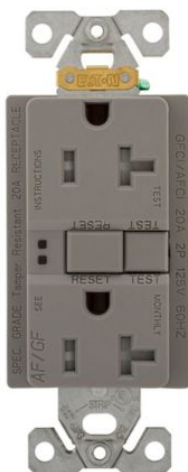

General specifications

Product Name	Catalog Number
Eaton AFGF receptacle	TRAFGF20GY
UPC	Product Length/Depth
032664747670	2.815 in
Product Height	Product Width
4.625 in	2.01 in
Product Weight	Certifications
0.401 lb	UL Listed
	CSA Certified
	cULus Listed
	NOM

defaultTaxonomyAttributeLabel

Device type

Receptacle

Type

Self-test

Amperage Rating

20A

Voltage rating

125V

Circuit interrupter type

AFGF

Contact material

Brass

Features

Tamper resistant

Application

Residential

Commercial

Wiring method

Back and side wire

Allowable wire size

#14 - 10 AWG

NEMA configuration

5-20R

Torque rating

16 lbf-inch

Environmental conditions

Tamper resistant

Mounting method

Flush

Color

Gray

Face/body material

PVC

Polycarbonate

Resources

Brochures

[AF/GF dual-purpose receptacles sell sheet](#)

Installation instructions

[Installing and testing an AF/GF receptacle](#)

Multimedia

[Ground Fault Circuit Interrupter \(GFCI\) demonstration](#)

Specifications and datasheets

[Eaton Specification Sheet - TRAFGF20GY](#)

[AF/GF duplex receptacle spec sheet](#)

Receptacle type

Two-pole, three-wire, grounding



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)