

Eaton XC A3 B3

Catalog Number: XC A3 B3

Eaton Crouse-Hinds series XC electric heater, 4,097 BTU/hr, 1.2 kW, Steel, 15A max., With built-in room thermostat, 240 Vac

General specifications

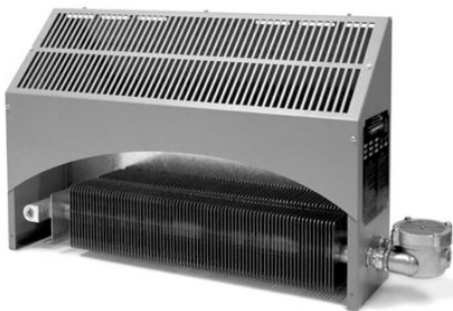


Photo is representative

Product Name	Catalog Number
Eaton Crouse-Hinds series XC electric heater	XC A3 B3
	UPC
	662276334236
Product Length/Depth	Product Height
37 in	20.3 in
Product Width	Product Weight
8.11 in	61.3 lb

Certifications and compliances

Area classification

Hazardous/Classified Locations

Standards type

NEC/CEC

IEC

NEC hazardous rating

Class I, Division 1

Class I, Zone 1

Class I, Division 2

Class I, Zone 2

NEMA Rating

7

Product specifications

Type

With built-in room thermostat

Power output

1.2 kW

Heat output

4,097 BTU/hr

Voltage rating

240Vac

Maximum total amperage

15 A

Material

Steel

Resources

Catalogs

[XC Series Explosionproof Electric Heaters catalog page](#)

Certification reports

[XC Explosionproof Electric Heaters UL certification](#)

Installation instructions

[IF 1729 - XC Series Explosionproof Electric Heaters](#)

Specifications and datasheets

[Eaton Specification Sheet - XC A3 B3](#)