



General Purpose Miniature Bells

AC and DC Models


13 Series

FEATURES

- > 1", 2" and 3" sizes
- > Long Life
- > Dust proof covers
- > Adjustable volume
- > Grounded frame
- > External binding posts
- > Chrome plate finish

Compact size and pleasant sound make these bells desirable for use in offices, apartment houses, intercom and telephone signaling, machinery and other OEM uses.

Suitable for AC powered security systems with battery standby.

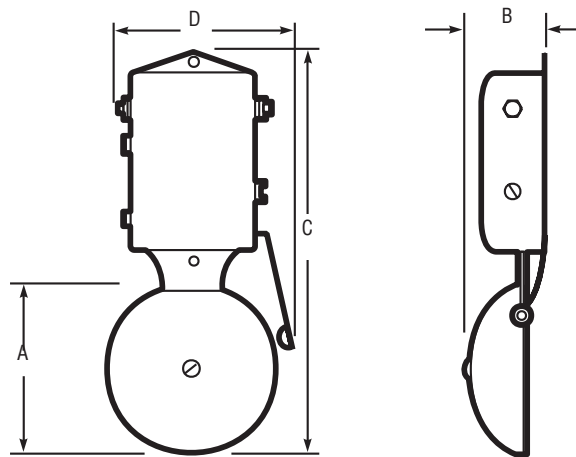

Cat No.	Size	Volts	Amps	VA	DC Coil Res (ohms)	dB at 1 m / 10 ft.	A	Dimension B	C	D
13-1AB	1" (25 mm)	5 - 10 DC	0.35	2.0	10	70 / 64	1 1/4" (32mm)	3/4" (19mm)	3 1/8" (79mm)	1 3/4" (44mm)
		6 - 12 AC	0.50	4.0	10					
13-1G1		24 DC	0.20	4.8	120					
13-1G5		24 AC	0.20	4.8	85					
13-2AB	2" (51 mm)	5-10 DC	0.40	2.5	8	71 / 65	1 3/4" (44mm)	1 1/16" (27mm)	3 29/32" (99mm)	2 1/32" (52mm)
		6-12 AC	0.50	4.0	8					
13-2G1		24 DC	0.25	6.0	90					
13-2G5		24 AC	0.25	6.0	56					
13-3AB	3" (76 mm)	5 - 10 DC	0.60	3.5	5	73 / 67	3" (76mm)	1 9/16" (40mm)	5 7/8" (149mm)	3 1/2" (89mm)
		6 - 12 AC	0.40	3.5	5					
13-3G1		24 DC	0.25	6	44					
13-3G5		24 AC	0.25	6	30					

D-04