

Sonos LED Beacon (DC)

A general purpose beacon for fire, security and industrial applications.

With the TimeSaver base, connections are made to the base during the initial wiring phase which results in faster and more reliable installation. The beacon head 'twists and clicks' into the base on commissioning, avoiding the wiring and connection problems associated with traditional alarm sounders.

Deep base units have weatherproof protection to IP65 and can be used in all locations both indoors and outdoors. The Sonos Beacon utilises a full faced, translucent case which provides a much larger lens area and a greater spread of light.

Sonos Beacon units have a deep or shallow red colour base as standard and are available with a red or amber lens.


Features

- High efficiency LED beacon consumes less than 5mA
- Simple 'First Fix' installation (no second fix wiring)
- Weatherproof to IP65 (deep base units)
- Synchronised flash
- White base option

Colour Options



Applications - Fire; security; industrial alarm

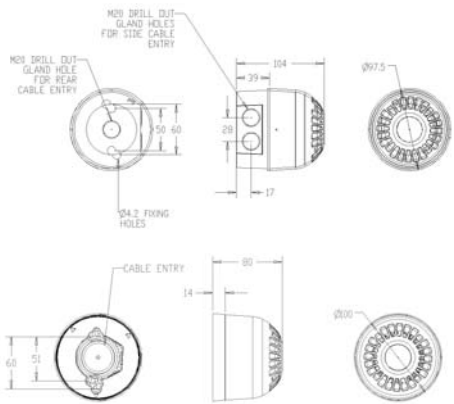

Deep Base

Shallow Base

- Fire
- Security
- Industrial
- Railway/Marine
- Hazardous Area
- Public Warning

Specifications

Part No.	Base	Colours	Voltage	Current
18-980507	shallow base	Red base, red lens	17-60V DC	5mA
18-980510	shallow base	Red base, amber lens	17-60V DC	5mA
18-980508	deep base	Red base, red lens	17-60V DC	5mA
18-980511	deep base	Red base, amber lens	17-60V DC	5mA

IP Rating: IP65 (deep base) IP21 (shallow base) **Rating:** Continuous **Operating Temp:** -25°C to +70°C
Construction: Flame Retardant Polycarbonate **Cable Entries:** 2 x 20mm cable glands (deep base)
Weight: 215g (shallow base) 250g (deep base)