

Three level sensor terminal blocks without ground connection

Compression clamp


 DIN 3

End stop th. 9,1 mm **BAMH** 0114 836.00
Other end stops : See Accessories section
 Rail  35 x 7,5 x 1 **PR30** prepunched 0173 220.05
 Rail  35 x 15 x 2,3 **PR4** 0168 500.12
 Rail  35 x 15 x 1,5 **PR5** prepunched 0101 598.26
Other rails : See Accessories section
Other accessories : See Accessories section

Notes

The use of some accessories may decrease the block's voltage rating. For more information, consult us.

Accessories

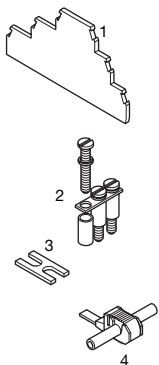


1 End section	grey
2 Assembled jumper bar	22 A
(without IP20 protection)	22 A
3 Connector plate	22 A
4 IDC jumper	24 A



R See section on markers marking method

D 2,5/6.DAL1

Spacing 6 mm +0,05 (.238")

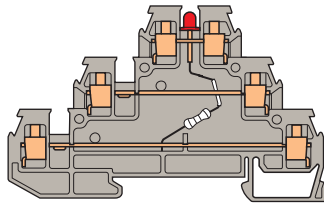

Three level block with LED indicator between upper and lower level (red 24V=)




Color	Type	Part numbers
Grey	 D 2,5/6.DAL1	0115 536.04

Characteristics

Wire size	NFC DIN	UL	CSA
Compression Solid wire	0,2-2,5 mm²	20-12 AWG	22-14 AWG
Stranded wire	0,22-2,5 mm²	20-12 AWG	22-14 AWG

Voltage			
Rated	380 V Gr.C	300 V (1)	300 V (1)
Pulse			
Pollution degree			
Current			
Rated	22 A	20 A	20 A
Wire size			
Rated / Gauge	2,5 mm²	12 AWG	14 AWG
Wire stripping length	Recomm. screwdriver	Recomm. torque	Protection
6 mm	3,5 mm	0,4-0,6 Nm	IP20
.24"	.138"	3.5-5.3 lb.in	NEMA 1


Type	Part numbers
FED3E th. 3,0 mm	0116 771.20
BJD6 2 poles	0178 024.25
BJD6 3 poles	0178 025.26
BJD6 4 poles	0178 026.27
BJD6 5 poles	0178 027.20
BJD6 10 poles	0178 032.25
BJD6 20 poles	0178 033.26
EL61	0177 812.17
AD2,5	0114 205.20

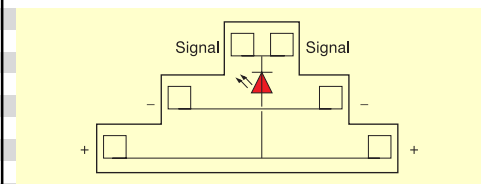

⑤ RC65 red - blank	0103 776.01
RC65 blue - blank	0103 775.00
Note : (1) 24 V DC on LED circuit.	

D 2,5/6.DAL2

Spacing 6 mm +0,05 (.238")

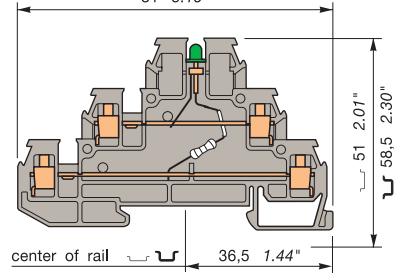

Three level block with LED indicator between lower levels (green 24V=)




Color	Type	Part numbers
Grey	 D 2,5/6.DAL2	0115 547.17

Characteristics

Wire size	NFC DIN	UL	CSA
Compression Solid wire	0,2-2,5 mm²	20-12 AWG	22-14 AWG
Stranded wire	0,22-2,5 mm²	20-12 AWG	22-14 AWG

Voltage			
Rated	380 V Gr.C	300 V (1)	300 V (1)
Pulse			
Pollution degree			
Current			
Rated	22 A	20 A	20 A
Wire size			
Rated / Gauge	2,5 mm²	12 AWG	14 AWG
Wire stripping length	Recomm. screwdriver	Recomm. torque	Protection
6 mm	3,5 mm	0,4-0,6 Nm	IP20
.24"	.138"	3.5-5.3 lb.in	NEMA 1

Type	Part numbers
FED3E th. 3,0 mm	0116 771.20
BJD6 2 poles	0178 024.25
BJD6 3 poles	0178 025.26
BJD6 4 poles	0178 026.27
BJD6 5 poles	0178 027.20
BJD6 10 poles	0178 032.25
BJD6 20 poles	0178 033.26
EL61	0177 812.17
AD2,5	0114 205.20

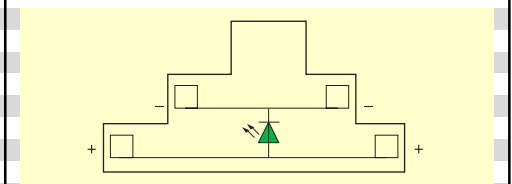

⑤ RC65 red - blank	0103 776.01
RC65 blue - blank	0103 775.00