
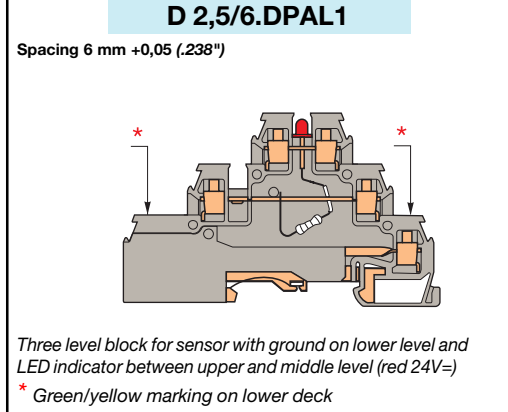


Three level sensor terminal blocks with ground connection

Compression clamp


 DIN 3

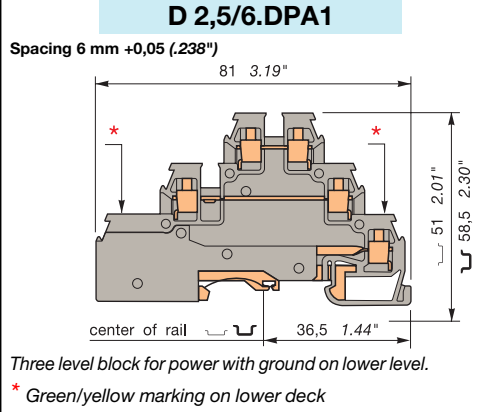


End stop	th. 9,1 mm	BAMH	0114 836.00
<i>Other end stops : See Accessories section</i>			
Rail	35 x 7,5 x 1	PR30 prepunched	0173 220.05
Rail	35 x 15 x 2,3	PR4	0168 500.12
Rail	35 x 15 x 1,5	PR5 prepunched	0101 598.26
<i>Other rails : See Accessories section</i>			
<i>Other accessories : See Accessories section</i>			

Notes

The use of some accessories may decrease the block's voltage rating. For more information, consult us.

Color	Type	Part numbers
Grey	 D 2,5/6.DPA1	0115 643.27

Color	Type	Part numbers
Grey	 D 2,5/6.DPAL1	0115 642.26

		NFC	DIN	UL	CSA
Compression clamp	Solid wire	0,2-2,5 mm ²		20-12 AWG	22-14 AWG
	Stranded wire	0,22-2,5 mm ²		20-12 AWG	22-14 AWG

		NFC	DIN	UL	CSA
Compression clamp	Solid wire	0,2-2,5 mm ²		20-12 AWG	22-14 AWG
	Stranded wire	0,22-2,5 mm ²		20-12 AWG	22-14 AWG

Voltage		380 V Gr.C	300 V	300 V
Rated				
Pulse				
Pollution degree				

Current		22 A	300A/1s	20 A	20 A
Rated	Short circuit				

Wire size		2,5 mm ²	12 AWG	14 AWG
Rated / Gauge				

Wire stripping length	Recomm. Screwdriver	Recomm. torque	Protection
6 mm	3,5 mm	0,4-0,6 Nm	IP20
.24"	.138"	3.5-5.3 lb.in	NEMA 1


Voltage		380 V Gr.C	300 V (1)	300 V (1)
Rated				
Pulse				
Pollution degree				

Current		22 A	300A/1s	20 A	20 A
Rated	Short circuit				

Wire size		2,5 mm ²	12 AWG	14 AWG
Rated / Gauge				

Wire stripping length	Recomm. Screwdriver	Recomm. torque	Protection
6 mm	3,5 mm	0,4-0,6 Nm	IP20
.24"	.138"	3.5-5.3 lb.in	NEMA 1



Accessories

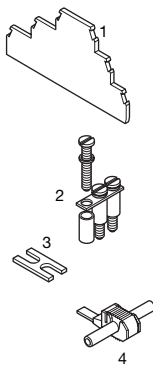

1 End section	grey	FED3E	th. 3,0 mm	0116 771.20
2 Assembled jumper bar (without IP20 protection)	22 A	BJD6	2 poles	0178 024.25
	22 A	BJD6	3 poles	0178 025.26
	22 A	BJD6	4 poles	0178 026.27
	22 A	BJD6	5 poles	0178 027.20
	22 A	BJD6	10 poles	0178 032.25
	22 A	BJD6	20 poles	0178 033.26
3 Connector plate	22 A	EL61		0177 812.17
4 IDC jumper	24 A	AD2,5		0114 205.20

Type	Part numbers
FED3E	th. 3,0 mm 0116 771.20
BJD6	2 poles 0178 024.25
BJD6	3 poles 0178 025.26
BJD6	4 poles 0178 026.27
BJD6	5 poles 0178 027.20
BJD6	10 poles 0178 032.25
BJD6	20 poles 0178 033.26
EL61	0177 812.17
AD2,5	0114 205.20

Type	Part numbers
FED3E	th. 3,0 mm 0116 771.20
BJD6	2 poles 0178 024.25
BJD6	3 poles 0178 025.26
BJD6	4 poles 0178 026.27
BJD6	5 poles 0178 027.20
BJD6	10 poles 0178 032.25
BJD6	20 poles 0178 033.26
EL61	0177 812.17
AD2,5	0114 205.20

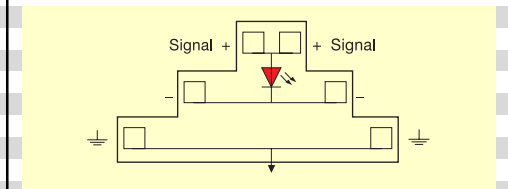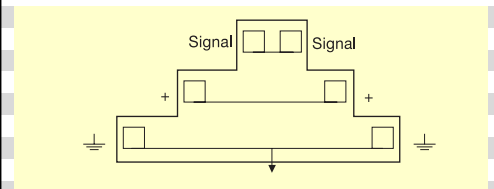

R See section on markers marking method

RC65	red - blank	0103 776.01
RC65	blue - blank	0103 775.00

RC65	red - blank	0103 776.01
RC65	blue - blank	0103 775.00

Note : (1) 24 V DC on LED circuit.