


Emergency Generator GFCI Cordsets



Side A

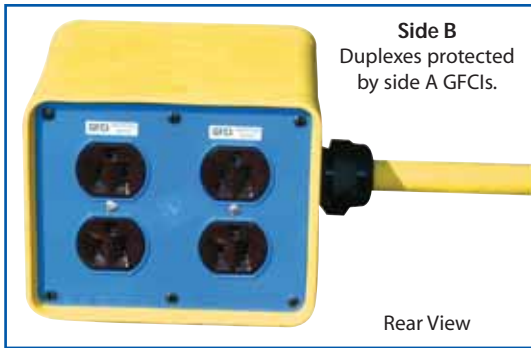


FEATURES:

- 120 & 240V, 3 & 4 Wire 20 & 30 AMP (L5-20, L5-30, L14-20 & L14-30 Plugs)
- Rubberized Box eliminates “hot” un-grounded dangerous metal quad boxes
- Heavy Duty Perma-Link™ Plug with rubberized body
- Heavy Duty SJ & SO cord for long service life
- GFCI Protection
- Heavy Duty cord strain relief at box stands up to rough duty
- 2, 25, 50 and 100 ft cord lengths keeps generator away from family and work area

NOTICE:

The NEC restricts the use of metal job boxes as temporary power cords

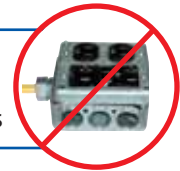

3 Wire Systems

Catalog Number	Rating	Plug	Cord Type	Box Config	Length
8V2123SJB6G2	120V 20 AMP	L5-20	#12/3 SJT Black	6000 Box w/ (1) GFCI 5-20 Duplex & (1) Protected 5-20 Duplex	2
8V2123SJB6GA					25
8V2123SJB6GB					50
8V3103SE6G2	120V 30 AMP	L5-30	#10/3 SEO Yellow	6000 Box w/ (1) GFCI 5-20 Duplex & (1) Protected 5-20 Duplex	2
8V3103SE6GA					25
8V3103SE6GB					50
8V3103SE6GD					100

4 Wire Systems

8Z2124SE8G2	240V 20 AMP	L14-20	#12/4 SEO Black	8000 Box w/ (2) GFCI 5-20 Duplex & (2) Protected 5-20 Duplex	2
8Z2124SE8GA					25
8Z2124SE8GB					50
8Z3104S08G2	240V 30 AMP	L14-30	#10/4 SO Yellow	8000 Box w/ (2) GFCI 5-20 Duplex & (2) Protected 5-20 Duplex	2
8Z3104S08GA					25
8Z3104S08GB					50
8Z3104S08GD					100

Other configurations available - call factory for details.

